



Hand tools

Puller, 2-arm



Puller, 2-arm


1787 F Quick-clamping puller · 2-arm

Made in Germany

• Quick-clamping device

- Nitrided spindle – extra hard maintenance-free – no lubrication necessary
- To be used as internal and external puller by inverting the hooks
- Quick-clamping allows fast and simple adjusting
- Very rugged, drop-forged pullers
- Setting scale for even adjusting of puller hooks

(E)

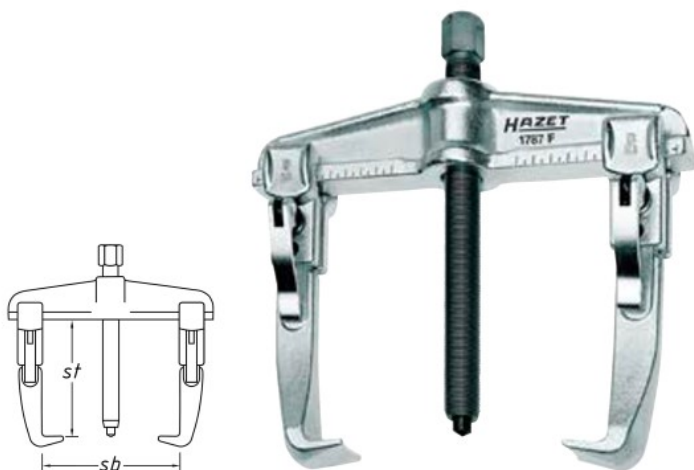


HAZET No.	Max. t.	sb mm	st mm	Spindle	EAN-No. 4000896+
1787 F- 9	3	90	100	M 14x1.5x140 mm	134151
1787 F-13	3	130	100	M 14x1.5x140 mm	134168
1787 F-16	5	160	150	G ½"x210 mm	134175
1787 F-20	5	200	150	G ½"x210 mm	134182
1787 F-25	7.5	250	200	G ¾"x280 mm	134199
1787 F-35	7.5	350	200	G ¾"x280 mm	136094

1787 Puller · 2-arm

Made in Germany

- To be used as internal and external puller by inverting the puller hooks
- Spindle G1 x 310
- Surface: galvanised

(E)

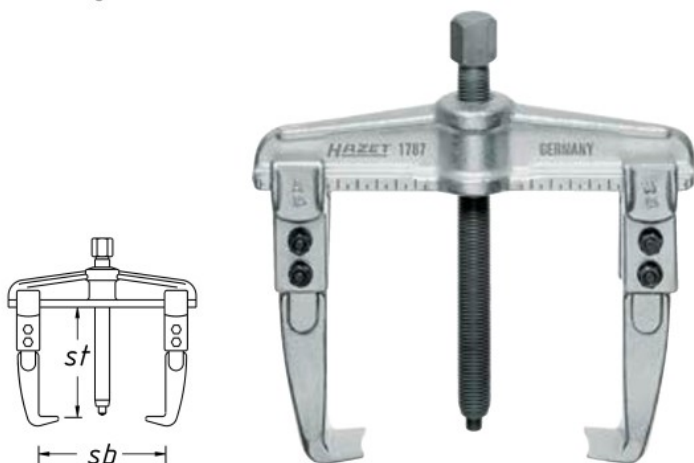

HAZET No.	Max. t.	sb mm	st mm	EAN-No. 4000896+
1787-52	10	520	208	136100

1787 F Quick-clamping puller set · 2-arm

Made in Germany

- Quick-clamping device
- 2-arm puller
- In display stand

(E)



1787 F
1787 F-9 • 1787 F-13
1787 F-16 • 1787 F-20
1787 F-25




HAZET No.		EAN-No. 4000896+
1787 F/5	5	133017

1787 S Puller set · 2-arm

Made in Germany

- Slim hooks
- "3 in 1"
- 6 slender forged hooks in 3 pairs of different lengths
- For working in areas with restricted access

(E)

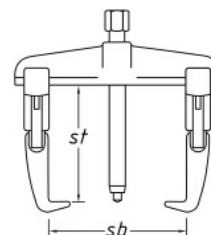


HAZET No.	sb mm	st mm	EAN-No. 4000896+
1787 S-1	130	100-200-250	133222

1783 Universal puller · 2-arm

Made in Germany

- Puller hooks can be used from both sides; hooks with one narrow side for areas with restricted access

- Application: Removing sprockets and ball bearings
- Automatic gripping of the puller hooks
- 2-arm design
- Surface: galvanised

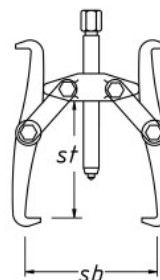

HAZET No.	Max. t.	sb mm	st mm	Spindle	EAN-No. 4000896+
1783-22	5	220	170	M 18x1.5x170 mm	136063