


N-55 PRECISION DIAGONAL CUTTER



- Cutting capacity: Copper wire 1.0mm φ
Copper stranded wire 0.9 mm²
- Hardness HRC: Body / 46
Blade / 58
- Weight: 40 g

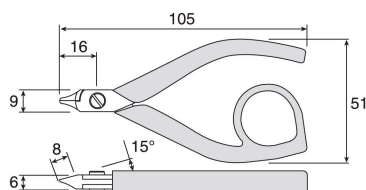

FULL FLUSH CUT




FULL FLUSH CUT ELASTOMER GRIPS SPRING

N-57 PRECISION DIAGONAL CUTTER



- Cutting capacity: Copper wire 1.0mm φ
Copper stranded wire 0.9 mm²
- Hardness HRC: Body / 46
Blade / 60
- Weight: 40 g

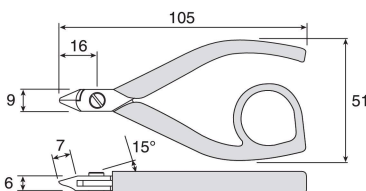

SEMI FLUSH CUT ELASTOMER GRIPS SPRING


N-58 PRECISION DIAGONAL CUTTER



- Cutting capacity: Copper wire 0.18 to 0.8 mm φ
(effective nose stop range)
- Hardness HRC: Body / 46
Blade / 60
- Weight: 40 g



The N-57 cutter is equipped with a lead stopper that catches the cuttings. This prevents accidents caused by scattered cuttings.

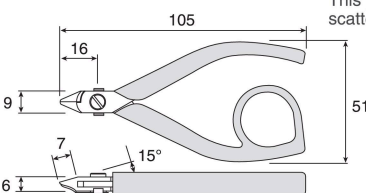


SEMI FLUSH CUT ELASTOMER GRIPS SPRING

P-51 PRECISION PLIERS



- Hardness HRC: 46
- Weight: 42 g
- Without serrations

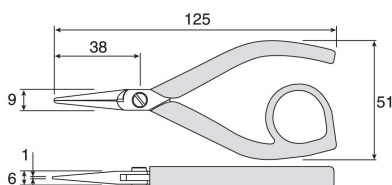

ELASTOMER GRIPS SPRING

- Cutters & Pliers
- Wire strippers
- Crimpers
- Tweezers
- Screwdrivers & Wrenches
- Metal working
- Parts boxes
- Tool cases
- Tool kit
- Soldering irons & Solder
- Parts & Solder removal equipment
- Measuring instruments
- Optical equipment
- Antistatic products
- Clean products
- Chemical products
- Maintenance & Safety products
- Precision series
- Miniature cutters
- Plastic cutters
- Standard cutters
- Scissors
- Wire cutters
- Miniature pliers
- Standard pliers
- Lineman's pliers
- Slip joint pliers