


- Cutters & Pliers
- Wire strippers
- Crimpers
- Tweezers
- Screwdrivers & Wrenches
- Metal working
- Parts boxes
- Tool cases
- Tool kits
- Soldering irons & Solder

# Cutters

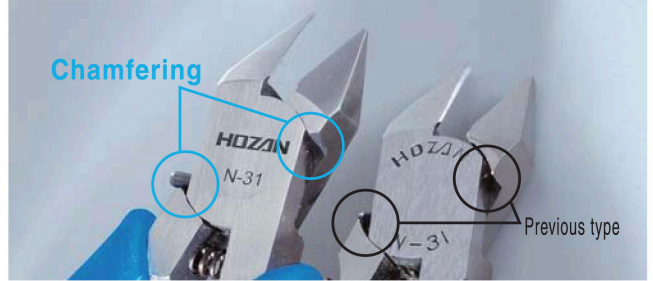

## Chamfering ensures working safety

Most of Hozan cutters and pliers feature chamfering of sharp edge at the joint area to minimize injuries and enhance work safety.  
(Applicable products: N-31, 32, 33, 34, 35; and P-34, 35)

### N-31 MINIATURE DIAGONAL CUTTER



- Cutting capacity: Copper wire 1.6mm  $\phi$   
Copper stranded wire 1.25 mm<sup>2</sup>
- Hardness HRC(blade): 57
- Weight: 40 g

ELASTOMER GRIPS SPRING



ELASTOMER GRIPS

Non carbon elastomer grip conforms to RCJS-5-1 (see page 141).  
Ground resistance  $R_g < 1 \times 10^{12} \Omega$


 


Antistatic products have an "ESD SAFE" label.

SPRING

Offers excellent durability and restorability, and enables continuous use with comfort.

Chamfering

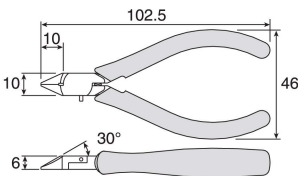

### N-34 MINIATURE DIAGONAL CUTTER



- A thin blade type of N-31.
- Cutting capacity: Copper wire 1.0mm  $\phi$   
Copper stranded wire 1.25 mm<sup>2</sup>
- Hardness HRC(blade): 57
- Weight: 40 g


ELASTOMER GRIPS SPRING

#### Replacement parts

#### COIL SPRING

Part no.	Compatible items
N-21-1	N-21 / P-14-125
N-31-1	N-31 / 33 / 34 / 36 P-34 / 35 / 38 / 39
N-32-1	N-32 / 35

■ Quantity: 10 pieces

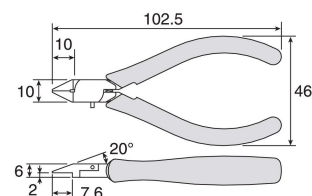

- Precision series
- Miniature cutters
- Plastic cutters
- Standard cutters
- Scissors
- Wire cutters
- Miniature pliers
- Standard pliers
- Lineman's pliers
- Slip joint pliers