


N-32 MINIATURE DIAGONAL CUTTER



- Cutting capacity: Copper wire 2.0mm φ
Copper stranded wire 2 mm²
- Hardness HRC(blade): 57
- Weight: 65 g

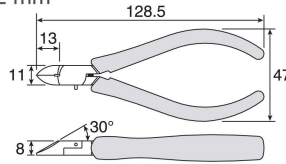


ELASTOMER GRIPS SPRING

N-35 MINIATURE DIAGONAL CUTTER



- Cutting capacity: Copper wire 1.6mm φ
Copper stranded wire 2 mm²
- Hardness HRC(blade): 57
- Weight: 65 g

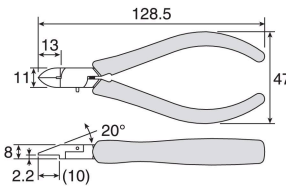


ELASTOMER GRIPS SPRING

N-36 MINIATURE END CUTTER



- Cutting capacity: Copper wire 1.0mm φ
Copper stranded wire 0.9 mm²
Plastic 1.5 mm φ
- Hardness HRC(blade): 56
- Weight: 58 g

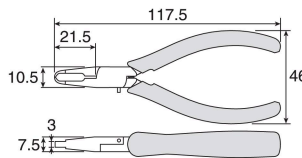


ELASTOMER GRIPS SPRING

N-33 MINIATURE END CUTTER



- Cutting capacity: Copper wire 1.0mm φ
Copper stranded wire 0.9 mm²
- Hardness HRC(blade): 57
- Weight: 45 g

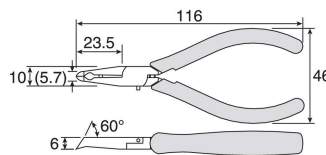


ELASTOMER GRIPS SPRING

N-21 PLASTIC CUTTER



- Cutting capacity: Plastic 5.0 mm φ
Copper wire 1.0 mm φ
Copper stranded wire 1.25 mm²
- Hardness HRC(blade): 56
- Weight: 90 g


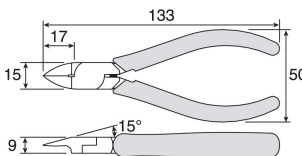


ELASTOMER GRIPS SPRING

N-993 CUTTING TWEEZERS



- Cutting capacity: Copper wire 0.08 to 0.3 mm φ
- Hardness HRC(blade): 58
- Material: Stainless
- Weight: 25 g

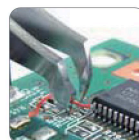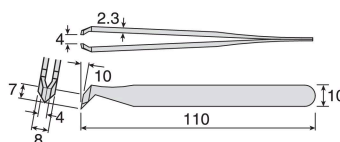

For jumper wire cutting



- Cutters & Pliers
- Wire strippers
- Crimpers
- Tweezers
- Screwdrivers & Wrenches
- Metal working
- Parts boxes
- Tool cases
- Tool kits
- Soldering irons & Solder
- Parts & Solder removal equipment
- Measuring instruments
- Optical equipment
- Antistatic products
- Clean products
- Chemical products
- Maintenance & Safety products
- Precision series
- Miniature cutters
- Plastic cutters
- Standard cutters
- Scissors
- Wire cutters
- Miniature pliers
- Standard pliers
- Lineman's pliers
- Slip joint pliers