



N-840 SNIPS (with serrated blade)

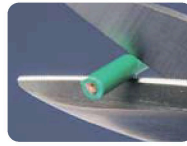

- Cutting capacity: Copper stranded wire 2 mm²
Aluminum plate 0.5mm
Coaxial cable 5C-2V
- Hardness HRC(blade): 59
- Weight: 60 g

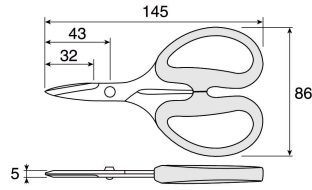


2 mm² stranded wire



Coaxial cable



Aramid fiber

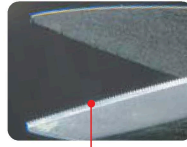



With serrated blade



N-838 SNIPS



- Cutting capacity: Copper stranded wire 2 mm²
Aluminum plate 0.5mm
- Hardness HRC(blade): 59
- Weight: 58 g

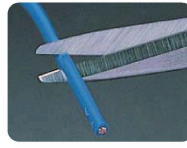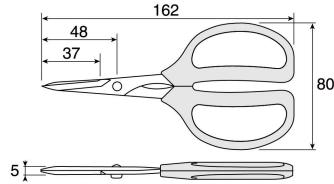

Stranded wire




Aluminum plate




N-839 SNIPS



- Cutting capacity: VCT wire 3.5 mm² (4 conductors)
VVR wire 3.5 mm² (3 conductors)
Aluminum plate 1.2mm
Copper stranded wire 8 mm²
- Hardness HRC(blade): 58
- Weight: 150 g

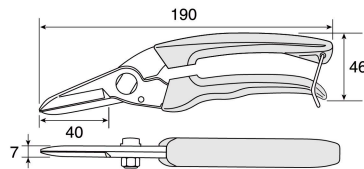

VVR wire

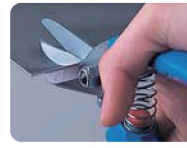


Aluminum plate



N-18 CABLE CUTTER



- Cutting capacity: VVF wire 2.0 mm φ (2 conductors)
IV wire 22 mm²
- Hardness HRC(blade): 53
- Weight: 167 g

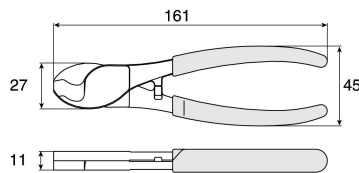

VVF wire




IV wire



N-16 WIRE CUTTER

- Cutting capacity: Wire 5 mm φ (steel, stainless)
- Hardness HRC(blade): 62
- Weight: 335 g

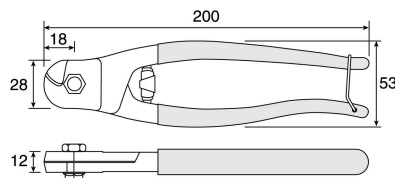

Stainless wire



Cutters & Pliers

Wire strippers

Crimpers

Tweezers

Screwdrivers & Wrenches

Metal working

Parts boxes

Tool cases

Tool kits

Soldering irons & Solder

Parts & Solder removal equipment

Measuring instruments

Optical equipment

Antistatic products

Clean products

Chemical products

Maintenance & Safety products

Precision series

Miniature cutters

Plastic cutters

Standard cutters

Scissors

Wire cutters

Miniature pliers

Standard pliers

Lineman's pliers

Slip joint pliers