


P-34 MINIATURE FLAT NOSE PLIERS

- Hardness HRC: 42
- Weight: 40 g
- Without serrations



ELASTOMER GRIPS

SPRING

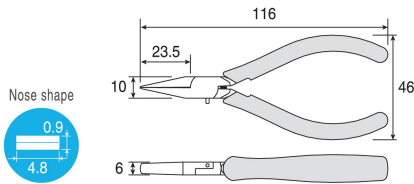


P-37 MINIATURE LONG NOSE PLIERS

- Hardness HRC: 46
- Weight: 60 g
- Without serrations



ELASTOMER GRIPS

SPRING

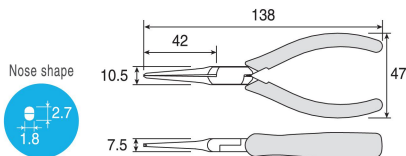


P-39 MINIATURE ROUND NOSE PLIERS

- Nose size: Tip diameter 1.2 mm ϕ
Base diameter 5 mm ϕ
- Hardness HRC: 46
- Weight: 58 g



ELASTOMER GRIPS


SPRING

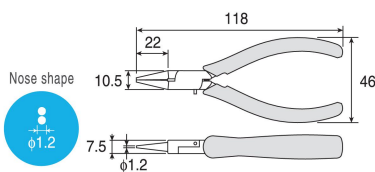

■ Related products

P-51 PRECISION PLIERS


- Hardness HRC: 46
- Weight: 42 g
- Without serrations

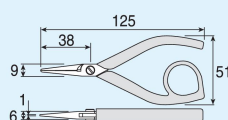

*For details, see page 9

P-899 TWEEZERS

- Thickness: 2.5 mm

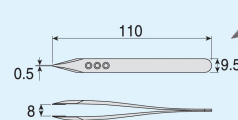

Has file-like teeth

*For details, see page 29