

Cutters & Pliers

Wire strippers

Crimpers

Tweezers

Screwdrivers & Wrenches

Metal working

Parts boxes

Tool cases

Tool kits

Soldering irons & Solder

Parts & Solder removal equipment

Measuring instruments

Optical equipment

Antistatic products

Clean products

Chemical products

Maintenance & Safety products

Precision series

Miniature cutters

Plastic cutters

Standard cutters

Scissors

Wire cutters

Miniature pliers

Standard pliers

Lineman's pliers

Slip joint pliers

P-15 LONG NOSE PLIERS WITH SIDE CUTTER

P-15-125

P-15-150


- Cutting capacity: Copper wire 2.6mm φ
Copper stranded wire 2 mm²

- Hardness HRC(blade): 58


- Weight: P-15-125 100 g

- P-15-150 125 g


- With serrations

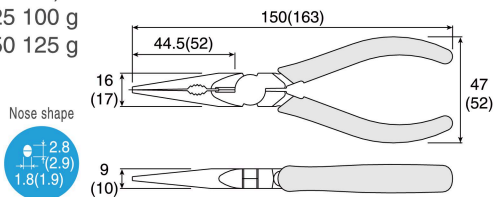

With serrated gripping hole (P-15-150 only)

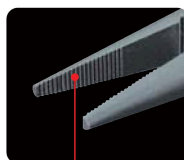

With serrations

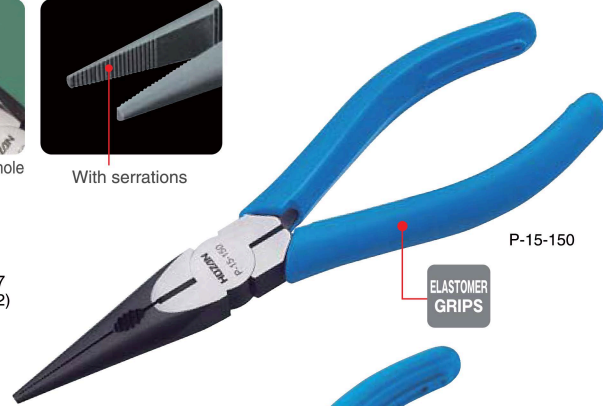

ELASTOMER GRIPS



CUTTER

ELASTOMER GRIPS

P-15-150

P-14 LONG NOSE PLIERS WITH SIDE CUTTER

P-14-125

P-14-150



- Cutting capacity: Copper wire 2.6mm φ
Copper stranded wire 2 mm²

- Hardness HRC(blade): 58


- Weight: P-14-125 100 g

- P-14-150 125 g

- With serrations

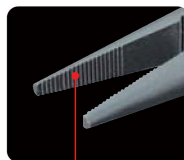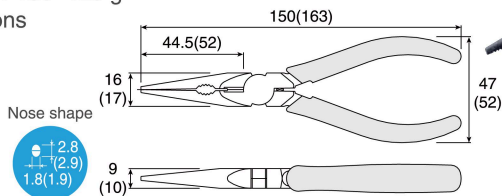

With serrations

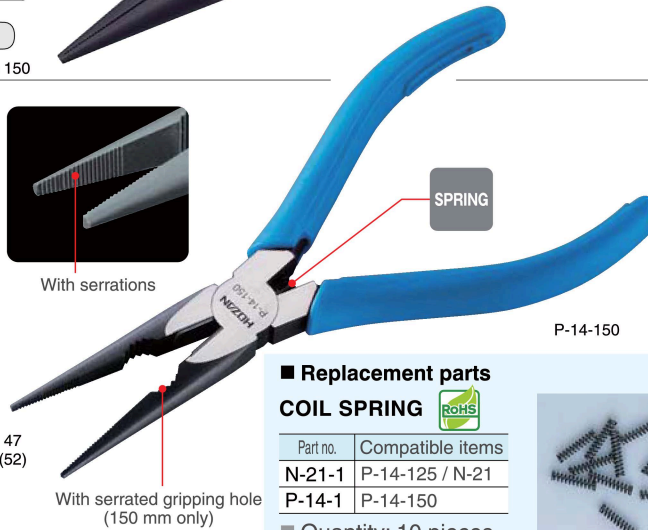

SPRING

ELASTOMER GRIPS

SPRING



CUTTER

P-14-150

■ Replacement parts

COIL SPRING

| Part no. | Compatible items |
|----------|------------------|
| N-21-1 | P-14-125 / N-21 |
| P-14-1 | P-14-150 |

- Quantity: 10 pieces





P-22 LONG NOSE PLIERS WITH SIDE CUTTER

- Cutting capacity: Copper wire 2.6mm φ
Copper stranded wire 2 mm²

- Hardness HRC(blade): 58

- Weight: 125 g

- With serrations

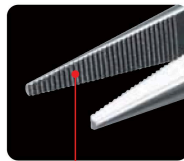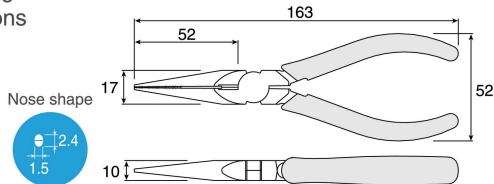

With serrations



ELASTOMER GRIPS




CUTTER

P-16 FLAT NOSE PLIERS

- Hardness HRC(tip): 45

- Weight: 115 g

- Without serrations

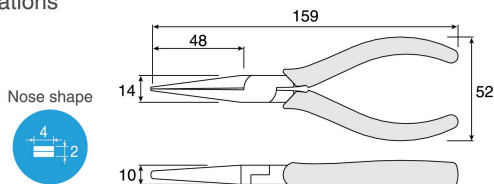


ELASTOMER GRIPS

P-12 BENT NOSE PLIERS

- Hardness HRC(tip): 45

- Weight: 115 g

- Without serrations

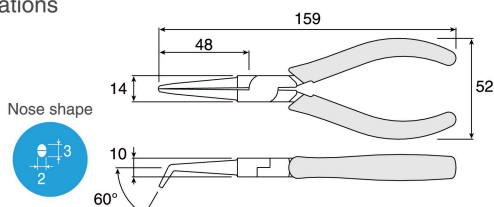

ELASTOMER GRIPS

⚠ Warning ● The handle cover is not insulated. Do not use where electrical currents exist.