


Band with holder

Application

- Grinding/polishing for iron and stainless. ●Inside polishing ●Deburring ●Chamfering
- Deburring pipe cross section ●Inside deburring

AC Band & Drum

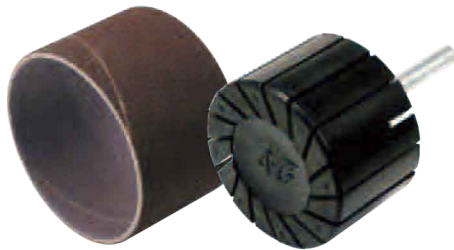

Abrasive tube fit in original rubber holder. Many size are available. It allows soft touch.



AC Band

item no.	dia × width(mm)	grit													Q'ty/box		
		24	36	40	60	80	100	120	150	180	240	320	400	600		800	1000
AC310	3×10				●	●	●	●	●	●	●	●					50
AC610	6×10				●	●	●	●	●	●	●	●					50
AC820	8×20			●	●	●	●	●	●	●	●	●					50
AC1020	10×20			●	●	●	●	●	●	●	●	●					50
AC1220	12×20			●	●	●	●	●	●	●	●	●					50
AC1520	15×20			●	●	●	●	●	●	●	●	●					50
AC1920	19×20			●	●	●	●	●	●	●	●	●					50
AC2525	25×25			●	●	●	●	●	●	●	●	●					50
AC3030	30×30			●	●	●	●	●	●	●	●	●					50
AC4530	45×30			●	●	●	●	●	●	●	●	●					50

AC Drum

item no.	dia × width(mm)	shaft dia × shaft length(mm)	RPM	Q'ty/box
AD310	3×10	3×35	25,000	10
AD610	6×10	3×35	25,000	10
AD8203	8×20	3×35	25,000	10
AD8206	8×20	6×40	25,000	10
AD10203	10×20	3×35	25,000	10
AD10206	10×20	6×40	25,000	10
AD12206	12×20	6×35	25,000	10
AD1520	15×20	6×35	20,000	10
AD1920	19×20	6×35	20,000	10
AD2525	25×25	6×35	18,000	10
AD3030	30×30	6×40	13,000	10
AD4530	45×30	6×40	9,000	10

