


Type : SJS


Elbow type (21MPa)

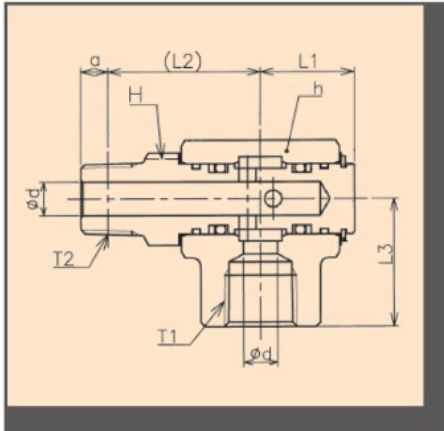

SJS5 * * - 4 * *

Unit : mm


Mod	T1 (Rc)	T2 (R)	d	L1	L2	L3	a	h	H
SJS502-402	1/4	1/4	5	19.5	31.5	30	6.01	22	14
SJS503-403	3/8	3/8	8	22	35.5	30	6.35	27	19
SJS504-404	1/2	1/2	11.5	24	40.5	35	8.16	32	22
SJS506-406	3/4	3/4	16	30	48.5	42	9.53	41	30
SJS508-408	1	1	20	36	57	46	10.39	46	36
SJS510-410	1 1/4	1 1/4	26	40	65.5	58	12.7	60	46

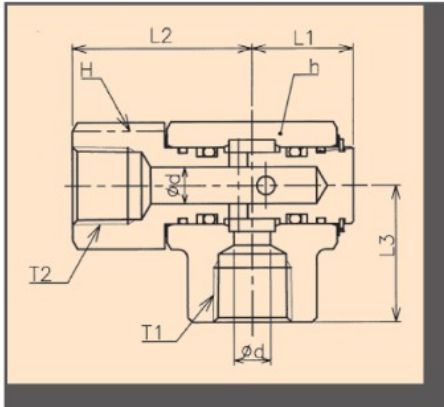

SJS5 * * - 5 * *

Unit : mm


Model Nos.	T1 (Rc)	T2 (Rc)	d	L1	L2	L3	h	H
SJS502-502	1/4	1/4	5	19.5	34.5	30	22	19
SJS503-503	3/8	3/8	8	22	39	30	27	24
SJS504-504	1/2	1/2	11.5	24	45.5	35	32	30
SJS506-506	3/4	3/4	16	30	55	42	41	36
SJS508-508	1	1	20	36	64.5	46	46	41
SJS510-510	1 1/4	1 1/4	26	40	75	58	60	55

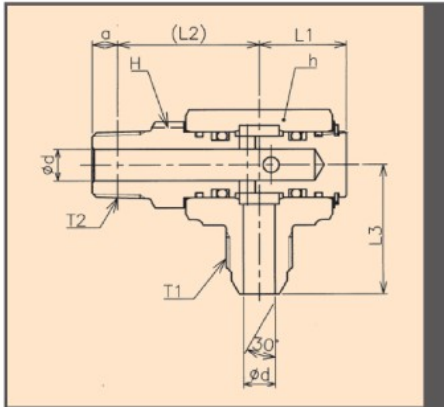

SJS6 * * - 4 * *

Unit : mm

Model Nos.	T1 (G)	T2 (R)	d	L1	L2	L3	a	h	H
SJS602-402	1/4	1/4	5	19.5	31.5	30	6.01	22	14
SJS603-403	3/8	3/8	8	22	35.5	33	6.35	27	19
SJS604-404	1/2	1/2	11.5	24	40.5	38	8.16	32	22
SJS606-406	3/4	3/4	16	30	48.5	42	9.53	41	30
SJS608-408	1	1	20	36	57	47	10.39	46	36
SJS610-410	1 1/4	1 1/4	26	40	65.5	63	12.7	60	46

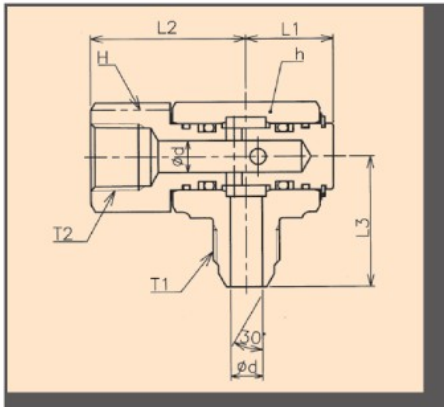

SJS6 * * - 5 * *

Unit : mm

Model Nos.	T1 (G)	T2 (Rc)	d	L1	L2	L3	h	H
SJS602-502	1/4	1/4	5	19.5	34.5	30	22	19
SJS603-503	3/8	3/8	8	22	39	33	27	24
SJS604-504	1/2	1/2	11.5	24	45.5	38	32	30
SJS606-506	3/4	3/4	16	30	55	42	41	36
SJS608-508	1	1	20	36	64.5	47	46	41
SJS610-510	1 1/4	1 1/4	26	40	75	63	60	55