
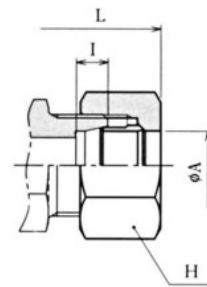


# ユニオン

UNION

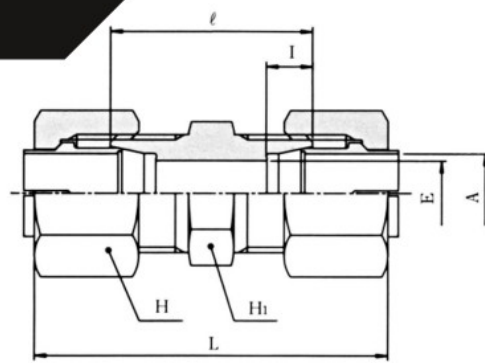

※印サイズの形状  
※NS Type

単位：mm/Unit: mm

継手の呼び Part No.	適用管外径 Out. Dia. of Applied Pipe A		E	六角対辺 Hex Width		I	ℓ	手締め(約) Fingertight Length (about) L	重量 Weight (kg)
	呼び径 Nominal sizes	外径 Out. Dia.		H <sub>1</sub>	H				
※KUA04-000N		4	2.5	12	12	6	20	35	0.022
KUA06-000E		6	4	14	14	7	30	51	0.042
KUA08-000E		8	6	17	17	7	31	52	0.059
KUA10-000E		10	8	17	19	7	31	54	0.068
KUA12-000E		12	10	19	22	7	31	54	0.093
KUA15-000E		15	12	24	27	7.5	36	61	0.165
KUA16-000E		16	13	27	30	7.5	36	61	0.216
KUA18-000E		18	14	27	32	8	36	61	0.227
KUA20-000E		20	17	30	36	8	38	63	0.305
KUA22-000E		22	18	32	36	9	38	63	0.279
KUA25-000E		25	20	36	41	10	39	66	0.395
KUA28-000E		28	22	41	46	10	43	71	0.535
KUA30-000E		30	25	41	46	10	43	72	0.512
KUA35-000E		35	28	46	55	11	44	79	0.788
※KUA38-000N		38	32	50	60	12	46	85	1.013
※KUA40-000N		40	32	55	60	12	55	94	1.137
※KUA42-000N		42	34	55	60	12	55	94	1.071
※KUA50-000N		50	40	65	75	12	60	103	1.909
※KUA11-000N	1/8	10.5	8	17	19	7	31	54	0.072
※KUA13-000N	1/4	13.8	11	22	24	7.5	36	60	0.130
※KUA17-000N	3/8	17.3	14	27	32	8	36	61	0.230
※KUA21-000N	1/2	21.7	18	32	36	9	38	63	0.287
※KUA27-000N	3/4	27.2	22	41	46	10	43	71	0.542
※KUA34-000N	1	34.0	28	46	55	11	44	79	0.801
※KUA43-000N	1 1/4	42.7	34	60	65	12	57	96	1.432
※KUA48-000N	1 1/2	48.6	40	65	75	12	60	103	1.942

注. 予告なしに、品質・性能・改善のため寸法を変更する事があります。

Note. Dimensions might be modified due to improvement of quality and performance.