


# SRN・SSS ねじ込み形管継手 / Threaded Pipe Fittings

## 径違いニップル SRN / Reducing Nipple SRN

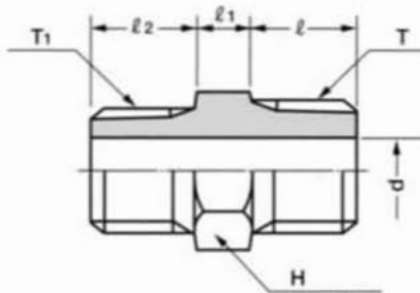


単位：mm/unit: mm

継手の呼び Part No.	T×T <sub>1</sub> (R)	d	H (六角) H (HEX)	ℓ	ℓ <sub>1</sub>	ℓ <sub>2</sub>	重量 (kg) Weight (kg)
SRN03-020F	3/8 × 1/4	7	19	14	8	13	0.045
○ SRN04-020F	1/2 × 1/4	7	24	17	9	13	0.078
○ SRN04-030F	1/2 × 3/8	9	24	17	9	14	0.079
○ SRN06-020F	3/4 × 1/4	7	30	19	10	13	0.13
○ SRN06-030F	3/4 × 3/8	9	30	19	10	14	0.14
○ SRN06-040F	3/4 × 1/2	12	30	19	10	17	0.14
○ SRN08-030F	1 × 3/8	9	36	22	11	14	0.25
○ SRN08-040F	1 × 1/2	12	36	22	11	17	0.25
○ SRN08-060F	1 × 3/4	16	36	22	11	19	0.25
○ SRN10-040F	1 1/4 × 1/2	12	46	24	12	17	0.45
○ SRN10-060F	1 1/4 × 3/4	16	46	24	12	19	0.44
○ SRN10-080F	1 1/4 × 1	20	46	24	12	22	0.44
○ SRN12-060F	1 1/2 × 3/4	16	50	24	14	19	0.59
○ SRN12-080F	1 1/2 × 1	20	50	24	14	22	0.59
○ SRN12-100F	1 1/2 × 1 1/4	28	50	24	14	24	0.55
○ SRN16-080F	2 × 1	20	65	28	16	22	1.09
○ SRN16-100F	2 × 1 1/4	28	65	28	16	24	1.03
○ SRN16-120F	2 × 1 1/2	32	65	28	16	24	1.01

○P処理品 / Parkerizing

## メスオスソケットA形 SSS / Street Socket Type A SSS

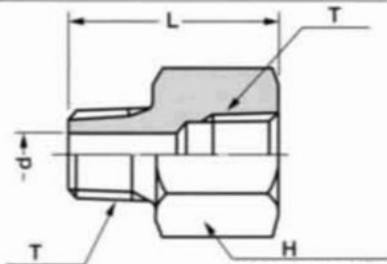

単位：mm/unit: mm

継手の呼び Part No.	T (R×Rc)	d	L	H (六角) H (HEX)	重量 (kg) Weight (kg)
SSS02-020J	1/4	7	33	22	0.058
SSS03-030J	3/8	9	36	24	0.075
○ SSS04-040J	1/2	12	45	32	0.16
○ SSS06-060J	3/4	16	50	36	0.22
○ SSS08-080J	1	20	58	46	0.42
○ SSS10-100J	1 1/4	28	67	55	0.65
○ SSS12-120J	1 1/2	32	69	65	0.96
○ SSS16-160J	2	40	79	75	1.39

○P処理品 / Parkerizing