


**pneumatic contacts  
with or without closing valve**




description	part No.
female contacts without closing valve	
- for tubes with internal $\varnothing$ 1,6 mm	<b>CX 1.6 PF</b>
- for tubes with internal $\varnothing$ 3 mm	<b>CX 3.0 PF</b>
- for tubes with internal $\varnothing$ 4 mm	<b>CX 4.0 PF</b>
- for tubes with internal $\varnothing$ 6 mm	<b>CX 6.0 PF</b>
male contacts without closing valve	
- for tubes with internal $\varnothing$ 1,6 mm	<b>CX 1.6 PM</b>
- for tubes with internal $\varnothing$ 3 mm	<b>CX 3.0 PM</b>
- for tubes with internal $\varnothing$ 4 mm	<b>CX 4.0 PM</b>
- for tubes with internal $\varnothing$ 6 mm	<b>CX 6.0 PM</b>
female contacts with closing valve	
- for tubes with internal $\varnothing$ 1,6 mm	<b>CX 1.6 VC</b>
- for tubes with internal $\varnothing$ 3 mm	<b>CX 3.0 VC</b>
- for tubes with internal $\varnothing$ 4 mm	<b>CX 4.0 VC</b>
- for tubes with internal $\varnothing$ 6 mm	<b>CX 6.0 VC</b>
male contact (use contacts without closing valve)	


**CX 1.6 PF/PM/VC**

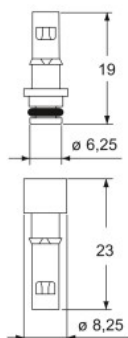

**CX 3.0 PF/PM/VC**

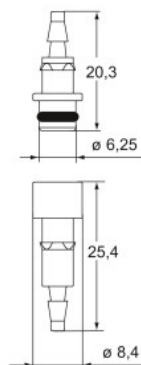

**CX 4.0 PF/PM/VC**

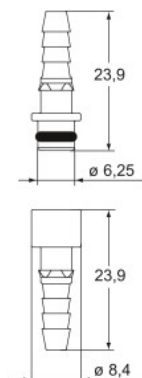

**CX 6.0 PF/PM/VC**

