


PLUM

ユニオンエルボ

Union elbow

樹脂製

Plastic body

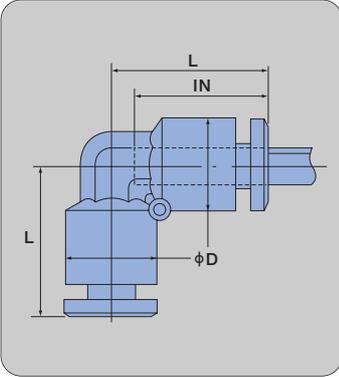

| 部品番号 PART NO. | 適用チューブ 外径 TUBE O.D. TO BE USED (mm) | φD (mm) | L (mm) | IN (mm) | 重量 WEIGHT (g) | 最小内径 ORIFICE (mm) | 有効断面積 EFFECTIVE SECTIONAL AREA (mm ²) | |
|------------------|---|------------|-----------|------------|---------------------|-------------------------|---|----------------------------------|
| | | | | | | | ナイロンチューブ NYLON TUBE | ウレタンチューブ POLYURETHANE TUBE |
| PLUM- 4-PM | 4 | 10.5 | 17 | 13 | 3 | 3 | 3.0 | 3.0 |
| PLUM- 6-PM | 6 | 12.5 | 18 | 14 | 5 | 4 | 6.5 | 6.5 |
| PLUM- 8-PM | 8 | 14.5 | 19 | 15 | 7 | 6 | 21.0 | 14.0 |
| PLUM-10-PM | 10 | 19 | 25 | 19 | 17 | 8 | 36.0 | 30.0 |
| PLUM-12-PM | 12 | 22 | 28 | 21 | 27 | 10 | 50.0 | 42.5 |