



Features


1. Higher anti-vibration performance than rubber pads

2. Convenient options

Typical applications


Air conditioner,
Pipe support and other industrial machinery

SM-20C~200C

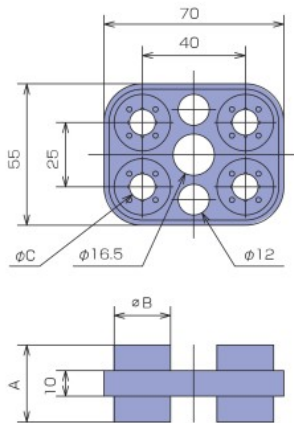

Product number	Standard dimensions mm			Permissible load N (kgf)	Spring constant N/mm (kgf/cm)
	A	B	C		
SM-20C	20	20	13	200 { 20}	59 { 60}
SM-40C	20	20	13	390 { 40}	110 { 110}
SM-100C	30	22	10	980 { 100}	250 { 250}
SM-200C	30	22	10	2000 { 200}	490 { 500}

SM-300~450

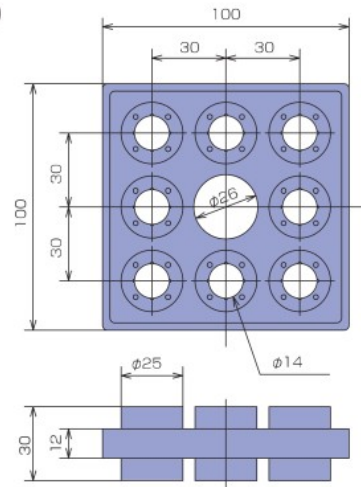


Product number	Permissible load N (kgf)	Spring constant N/mm (kgf/cm)
SM-300	2900 { 300}	880 { 900}
SM-450	4400 { 450}	1180 { 1200}


Options

Plate


for SM-20C to 200C
SM-P-S

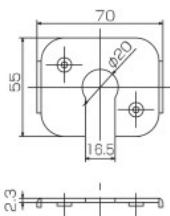

for SM-300 to 450
SM-P-L

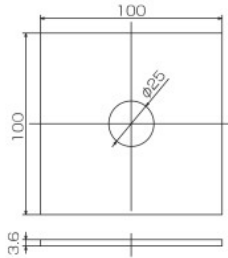

Rubber bush with metal washer

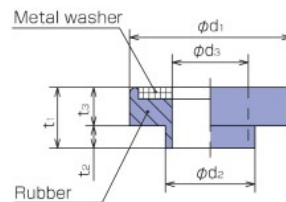

Product number	Standard dimensions mm					
	t_1	t_2	t_3	d_1	d_2	d_3
SM-B10	8.6	4	4.6	26	12.5	10.5
SM-B12	11.3	5	6.3	30	14.5	12.5
SM-B16	13.6	5	8.6	36	19	17
SM-B20	15.2	6	9.2	44	23	21
SM-B24	17.5	6	11.5	52	27.5	25.5

Plate is hot dip galvanized and RoHS-satisfied. Metal washer is SUS.

Usage

1. The SM-20C to 200C types can be easily slit with utility knife. You can easily, then, put them into an established machine's leg.
2. You must use the SM type with the optional plate in case that your machine's weight is not evenly distributed to the whole surface of the SM type.
3. Please increase the intensity of fitting parts and anchor bolts for more earthquake-resistance.

Instruction images

