


SIDE CUTTING PLIERS

1050 ^{JIS}


Side cutting pliers

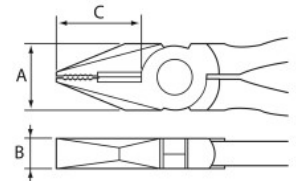

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Steel wire	Copper wire
⑩ 1050-150	150	22.0	12.5	26.0	200	2.0	3.0
⑩ 1050-175	175	23.5	13.5	30.5	275	2.6	3.5
⑩ 1050-200	200	26.5	14.5	32.0	375	3.2	4.0

1050H ^{JIS}


Side cutting pliers

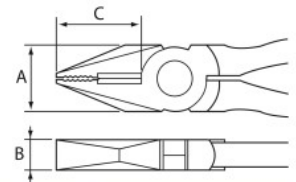

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Steel wire	Copper wire
⑩ 1050H-150	150	22.0	12.5	26.0	210	2.0	3.0
⑩ 1050H-175	175	23.5	13.5	30.5	285	2.6	3.5
⑩ 1050H-200	200	26.5	14.5	32.0	385	3.2	4.0

2050



High leverage side cutting pliers

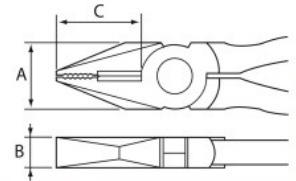

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Steel wire	Copper wire
2050-185	185	25.5	13.5	33.0	290	3.2	4.0
2050-225	225	27.0	14.5	35.0	370	3.6	4.5

2060 2060N


High leverage side cutting pliers
<with crimping die>

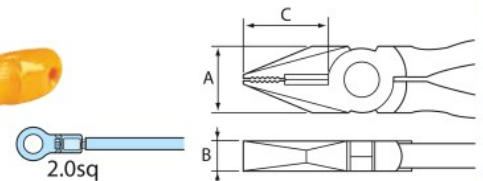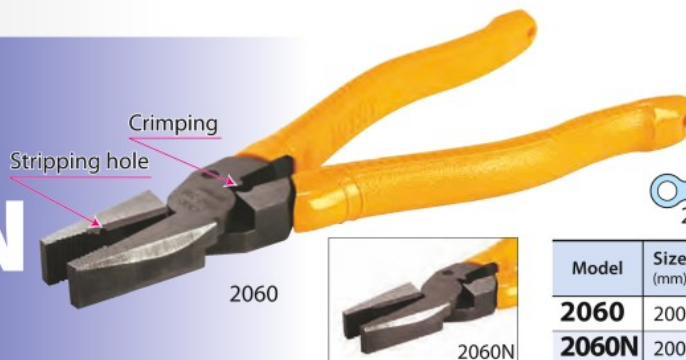

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Steel wire	Copper wire
2060	200	25.5	13.5	37.0	293	3.2	4.0
2060N	200	25.5	13.5	37.0	300	3.2	4.0

2060U

VA cutting pliers
<with crimping die>

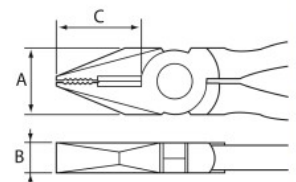

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Copper wire	VVF wire
2060U	200	25.5	13.5	37.0	285	4.0	φ2.0×3.0