


LONG NOSE SIDE CUTTING PLIERS & PLIERS

105

JIS

Long nose side cutting pliers

Spring Loaded

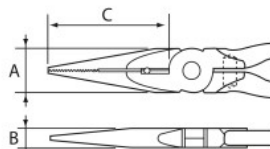


Model	Size (mm)	Dimensions (mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Steel wire	Copper wire
^{JIS} 105-150	150	17.0	10.5	50.0	115	1.5	2.6
105-175	175	19.0	10.5	59.0	150	2.0	3.0

105H

JIS

Long nose side cutting pliers

Spring Loaded

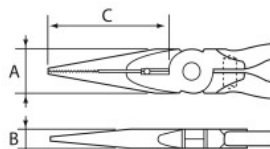


Model	Size (mm)	Dimensions (mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Steel wire	Copper wire
^{JIS} 105H-150	150	17.0	10.5	50.0	130	1.5	2.6
105H-175	175	19.0	10.5	59.0	165	2.0	3.0

150

Long nose side cutting pliers
◀slim type▶

Spring Loaded


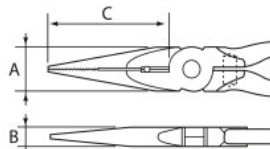


Model	Size (mm)	Dimensions (mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Steel wire	Copper wire
150	150	12.0	7.5	57.5	65	1.2	2.0

105F

Flat nose pliers

 Spring Loaded

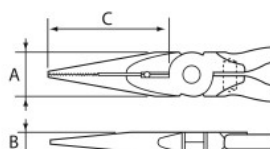

Model	Size (mm)	Dimensions (mm)			Weight (g)
		A	B	C	
105F-150	150	17.0	10.0	50.0	110
105F-175	175	19.5	11.5	59.0	160