

NIPPERS FOR CUTTING PLASTICS

HOT SELLER

Section of blade

Round type

Flat type


 
Angle type

170S

Angled plastic nippers

Spring Loaded

Flat type

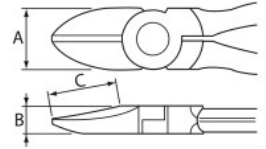


Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)
		A	B	C		Plastics
170S	150	15.0	10.0	22.0	120	5.0

99

Heavy-duty plastic nippers

Spring Loaded

Round type

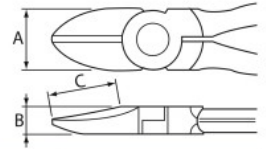

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)
		A	B	C		Plastics
99-150	150	22.0	12.5	18.0	185	8.0
99-175	175	24.0	12.5	23.0	235	9.0
99-200	200	26.0	13.5	27.0	310	10.0


99S

Heavy-duty plastic nippers
<with adjustable stopper>

Spring Loaded

Stopper

Round type

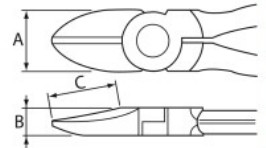

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)
		A	B	C		Plastics
99S-150	150	22.0	12.5	18.0	185	8.0
99S-175	175	24.0	12.5	23.0	240	9.0
99S-200	200	26.0	13.5	27.0	315	10.0


99SF

Heavy-duty plastic nippers
<with adjustable stopper>

Spring Loaded

Stopper

Flat type

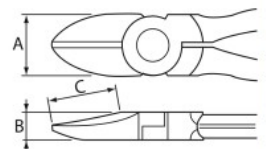

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)
		A	B	C		Plastics
99SF-150	150	22.0	12.5	20.0	185	8.0
99SF-175	175	24.0	12.5	24.0	240	9.0
99SF-200	200	25.5	13.5	28.0	315	10.0