

NIPPERS FOR CUTTING PLASTICS

HOT SELLER

Section of
blade

Round type

Flat type


Angle type

66S

Plastic nippers

Spring Loaded

Round
type

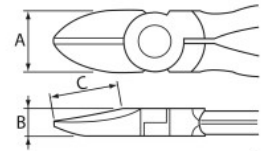

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)
		A	B	C		Plastics
66S	150	17.0	10.0	18.0	130	5.0

68S

 
Narrow nose plastic nippers

Spring Loaded

Round
type



For cutting in
narrow spaces.




Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)
		A	B	C		Plastics
68S	125	12.5	8.0	12.0	70	2.0

M11

Miniature plastic
cutting nippers

Spring Loaded

Round
type

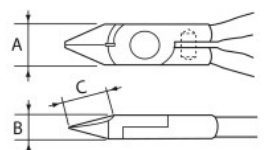


Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)
		A	B	C		Plastics
M11	125	14.0	8.0	15.0	75	3.0

M12

Miniature plastic
cutting nippers

Spring Loaded

Round
type

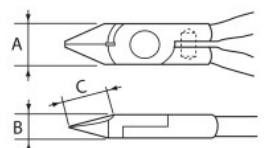

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm)
		A	B	C		Plastics
M12	125	12.5	8.5	12.0	75	3.0