


END CUTTING PLASTICS NIPPERS

R-CUT NIPPERS FOR CUTTING PLASTICS

23EF

End cutting plastic nippers

Spring Loaded

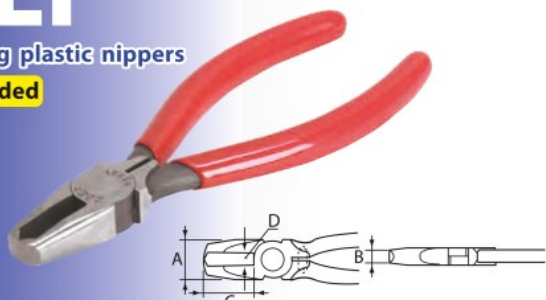


Model	Size (mm)	Dimensions (mm)				Weight (g)	Cutting capacity (φmm)	
		A	B	C	D		Plastics	
23EF	130	17.0	7.0	20.0	6.0	105		3.0

2000EF

End cutting plastic nippers

Spring Loaded

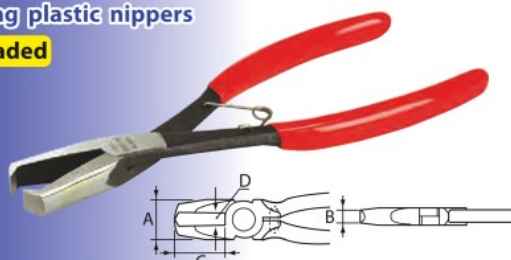


Model	Size (mm)	Dimensions (mm)				Weight (g)	Cutting capacity (φmm)	
		A	B	C	D		Plastics	
2000EF	190	18.0	8.0	35.0	20~90	175		3.0

24EF

End cutting plastic nippers

Spring Loaded

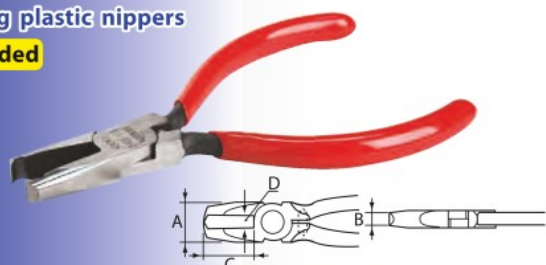


Model	Size (mm)	Dimensions (mm)				Weight (g)	Cutting capacity (φmm)	
		A	B	C	D		Plastics	
24EF	115	13.0	5.5	20.0	3.0	65		3.0

PG20

Pin gate plastic nippers
<with adjustable stopper>

Spring Loaded

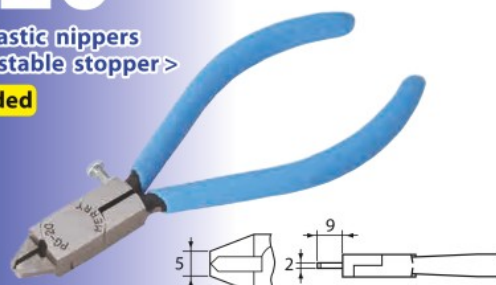

Model	Size (mm)	Weight (g)	Cutting capacity (φmm)	
			Plastics	
PG20	125	70		1.0

25EF

End cutting plastic nippers

Spring Loaded




Model	Size (mm)	Dimensions (mm)				Weight (g)	Cutting capacity (φmm)	
		A	B	C	D		Plastics	
25EF	145	17.0	5.5	31.0	4.0	110		3.0

CX25R

R-cut plastic nippers
<with adjustable stopper>

Spring Loaded

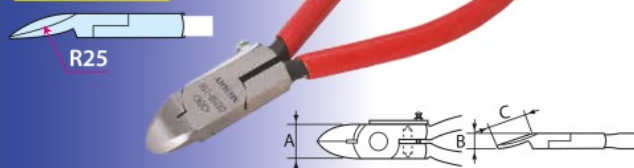

Model	Size (mm)	Dimensions (mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Plastics	
CX25R	150	16.0	8.5	13.0	110		5.0

26EF

End cutting plastic nippers

Spring Loaded




Model	Size (mm)	Dimensions (mm)				Weight (g)	Cutting capacity (φmm)	
		A	B	C	D		Plastics	
26EF	140	17.0	7.0	27.0	7.0	110		3.0

HW25R

R-cut plastic nippers
<with adjustable stopper>

Spring Loaded

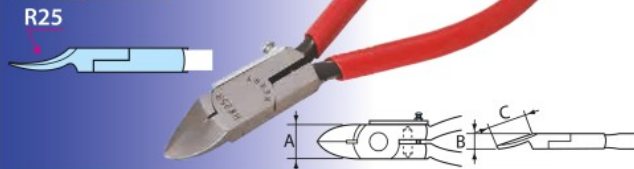

Model	Size (mm)	Dimensions (mm)			Weight (g)	Cutting capacity (φmm)	
		A	B	C		Plastics	
HW25R	150	16.0	8.5	16.0	110		5.0