

# NIPPERS FOR CUTTING PLASTICS OTHERS

Section of blade

Round type

Flat type


Angle type

## 550SF

Box joint plastic nippers

Spring Loaded

Round type

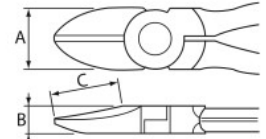


Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm) Plastics
		A	B	C		
550SF-125	125	14.0	14.5	21.5	95	3.0
550SF-150	150	15.0	17.0	24.0	125	5.0

## 140S

Flat plastic nippers  
◀with adjustable stopper▶

Spring Loaded

Flat type

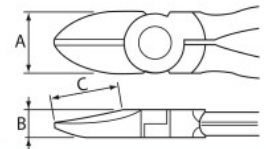


Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm) Plastics
		A	B	C		
140S	130	12.5	7.5	11.0	70	3.0

## 170PL

Smooth plastic nippers

Spring Loaded

Flat type

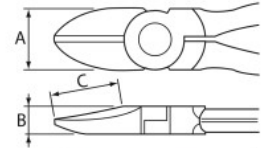


Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm) Plastics
		A	B	C		
170PL	150	16.0	9.0	24.0	112	5.0

## 02SP

Tip edge nippers

Spring Loaded

Round type

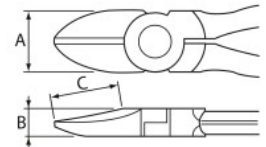


Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm) Plastics
		A	B	C		
02SP	125	12.0	7.5	6.0	75	2.0

## L40

Long handle nippers

Spring Loaded

Flat type

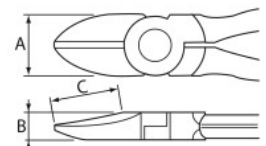

Model	Size (mm)	Dimensions(mm)			Weight (g)	Cutting capacity (φmm) Plastics
		A	B	C		
L40	190	17.0	9.0	19.0	150	5.0