

Stainless-steel Round-hole PIJON


φ8~20 8 Sizes

3S = SUS 303 Anti-rust and corrosion resistance

4S = SUS 304 Non-magnetism, heat-resistance, chemical-resistance

It can be slide with a round hole, a turning is flexible, and a flexible assembling is given.


An assembling with a square hole is freely to meet present conditions.

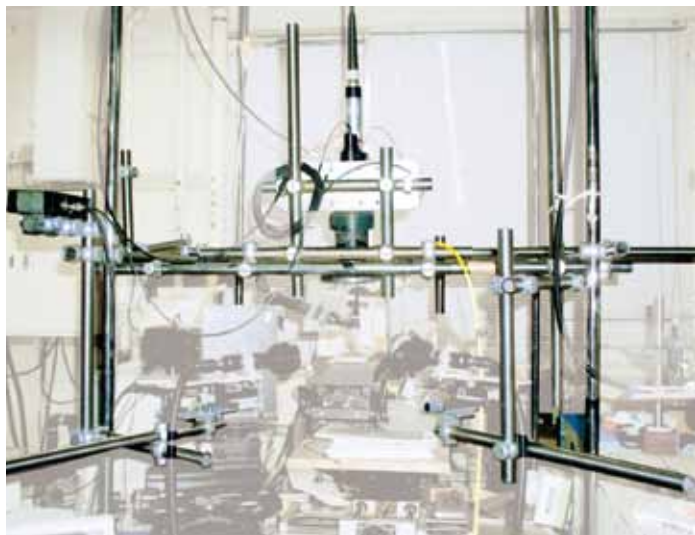


A production of a frame for a different purpose is available.

200

for right-angle shaft attachment

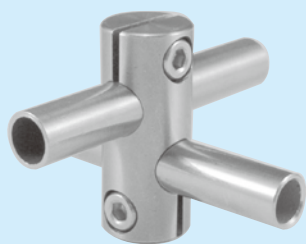

Cross 90° hole

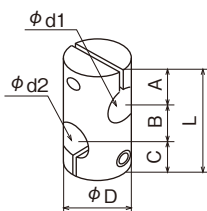


SUS 303	φd1	φd2	φD	L	A	B	C	Cap screw
PE3S200	8	8	13	36	13	10	13	M4
PC3S200	9	9	15	36	13	10	13	M4
PF3S200	10	10	15	37	13	11	13	M4
PG3S200	12	12	22	42	14	14	14	M4
PJ3S200	13	13	22	42	14	14	14	M4
PN3S200	16	16	25	53	17.5	18	17.5	M5
PL3S200★	19.1	19.1	30	61	20	21	20	M5
PQ3S200	20	20	30	61	20	21	20	M5

SUS 304	φd1	φd2	φD	L	A	B	C	Cap screw
PE4S200	8	8	13	36	13	10	13	M4
PC4S200	9	9	15	36	13	10	13	M4
PF4S200	10	10	15	37	13	11	13	M4
PG4S200	12	12	22	42	14	14	14	M4
PJ4S200	13	13	22	42	14	14	14	M4
PN4S200	16	16	25	53	17.5	18	17.5	M5
PL4S200★	19.1	19.1	30	61	20	21	20	M5
PQ4S200	20	20	30	61	20	21	20	M5


★ = φd1, φd2 tolerance is 0 / -0.05

204

for free assembly with other parts Insert the boss

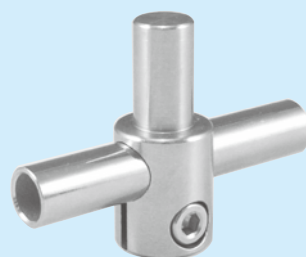

boss

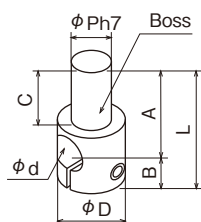

SUS 303	φd	φP	φD	L	A	B	C	Cap screw
PE3S204	8	8	13	35	22	13	16	M4
PC3S204	9	9	15	35	22	13	16	M4
PF3S204	10	10	15	37	24	13	17	M4
PG3S204	12	12	22	46	32	14	23	M4
PJ3S204	13	13	22	46	32	14	23	M4
PN3S204	16	16	25	54	36	18	25	M5
PL3S204★	19.1	19	30	63	43	20	30	M5
PQ3S204	20	20	30	63	43	20	30	M5

SUS 304	φd	φP	φD	L	A	B	C	Cap screw
PE4S204	8	8	13	35	22	13	16	M4
PC4S204	9	9	15	35	22	13	16	M4
PF4S204	10	10	15	37	24	13	17	M4
PG4S204	12	12	22	46	32	14	23	M4
PJ4S204	13	13	22	46	32	14	23	M4
PN4S204	16	16	25	54	36	18	25	M5
PL4S204★	19.1	19	30	63	43	20	30	M5
PQ4S204	20	20	30	63	43	20	30	M5

★ = φd tolerance is 0 / -0.05