


# SHB-EL / SHBS Hexagon Post



[WEB Selection Tool](#)  
 [WEB CAD Download](#)  
 [SUS Stainless steel](#)

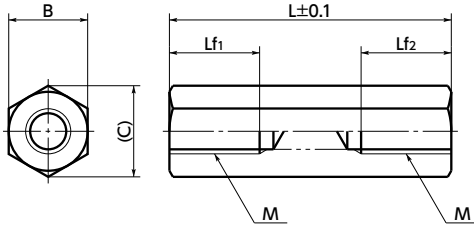

- Hexagon post for both-side female screw.
- Material/Finish ◀1 ▶ RoHS Compliant

	SHB-EL Made of Steel	SHBS Made of Stainless Steel
Main body	SUM22L Electroless Nickel Plating	SUS304

## Dimensions

Unit : mm

Part Number Steel	Part Number Stainless steel	M <span style="color:red">◀2</span> (coarse thread)	B	C	Lf1	Lf2	Mass (g)
SHB-M3-EL	SHBS-M3	M3	6	6.9	6	6	2.9 - 9
SHB-M4-EL	SHBS-M4	M4	7	8.1	8	8	5 - 25
SHB-M5-EL	SHBS-M5	M5	8	9.2	10	10	5.5 - 40
SHB-M6-EL	SHBS-M6	M6	10	11.5	12	12	11 - 98
SHB-M8-EL	SHBS-M8	M8	13	15	16	16	27 - 168

SHB-EL Made of Steel   SHBS Made of Stainless Steel

Part Number	L (mm) <span style="color:red">◀3</span>														
	15	20	25	30	35	40	45	50	60	70	80	90	100	120	150
SHB-M3-EL	●	●	●	●	●	●									
SHB-M4-EL		●	●	●	●	●	●	●	●	●	●				
SHB-M5-EL		●	●	●	●	●	●	●	●	●	●	●	●		
SHB-M6-EL			●	●	●	●	●	●	●	●	●	●	●	●	●
SHB-M8-EL					●	●	●	●	●	●	●	●	●	●	●
SHBS-M3	●	●	●	●	●	●									
SHBS-M4		●	●	●	●	●	●	●	●	●	●				
SHBS-M5		●	●	●	●	●	●	●	●	●	●	●	●		
SHBS-M6			●	●	●	●	●	●	●	●	●	●	●	●	●
SHBS-M8					●	●	●	●	●	●	●	●	●	●	●

- Part number specification

**SHB-M4-40-EL**



Cleanroom Wash & Packaging → P.792	Screw Length Adjustment → P.796	Vibration Resistant → P.795	Laser Marking → P.806
Available / Add'l charge	Not Available	Not Available	Available / Add'l charge