

SET/SETS


Hexalobular Socket Head Cap Screws with Extreme Low Profile

WEB Selection Tool

WEB CAD Download

Protrusion

SUS Stainless steel

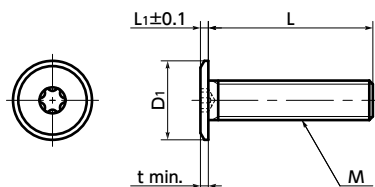

● Application

Reducing the size of equipment and devices

● Material/Finish

RoHS Compliant

	SET-NI	SET-BNI	SETS
Main	SWCH	SWCH	SUSXM7
Body	Nickel Plating	Black Nickel Plating	(S.S. grade : A2)



- Hexalobular* socket head cap screws with extra low profiles.

- Intended for reducing the size of devices and applications with limited overhead space.

- The hexalobular* shape can withstand high tightening torque. ➔ P.712

*The hexalobular shape is prescribed by JIS B 1015 : 2008 (ISO 10664 : 2005) "Hexalobular internal driving feature for bolts and screws"

- Install and remove by using **SKX** Specialty Hexalobular Key. ➔ P.715



- Also, products with special specifications such as ventilation holes, dimensions, shapes, materials, surface treatments, cleanroom washing & packaging are available.

➔ P.544



SET-NI Steel - Nickel Plating

Unit : mm

Part Number	M	2	L	3			D1	L1	Applicable wrench	Hexalobular Socket No.	t	Max. Torque (N·m)	Mass (g)
SET-M3-NI	M3	6	8	10			7	0.8	SKX-6	6	0.75	0.7	0.39 - 0.56
SET-M4-NI	M4	6	8	10	12	16	8	0.9	SKX-8	8	0.9	2.3	0.65 - 1.4
SET-M5-NI	M5		8	10	12	16	9	1	SKX-10	10	1	4	0.73 - 1.7

Part Number	Qty*1 per pack
SET-M3-NI	20
SET-M4-NI	20
SET-M5-NI	20

*1 The minimum order quantity is 1 piece. ➔ P.794

1 Individual Sales ➔ P.794	Cleanroom Wash & Packaging ➔ P.792	Screw Length Adjustment ➔ P.796	Vibration Resistant ➔ P.795	Modification process for captive use ➔ P.791
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Please feel free to contact us