


●鋼、鋳鉄の高効率加工ができます。

Able to handle drilling in Steel and Cast Iron efficiently.

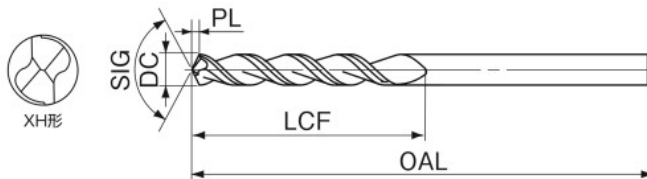

LIST 6536

オーダ方法 商品記号

単位 (Unit) : mm

| 商品記号 Code | 直径 DC | 溝長 LCF | 全長 OAL | 先端 PL | 在庫 Stock | 参考価格(円) Price (¥) |
|--------------|----------|-----------|-----------|----------|-------------|----------------------|
| AGPSD1.0 | 1.0 | 12 | 34 | 0.3 | | 969 |
| AGPSD1.1 | 1.1 | 14 | 36 | | | 1,140 |
| AGPSD1.2 | 1.2 | | | | | 1,080 |
| AGPSD1.3 | 1.3 | 16 | 38 | 0.4 | | 1,140 |
| AGPSD1.4 | 1.4 | | | | | 1,140 |
| AGPSD1.5 | 1.5 | 18 | 40 | | | 958 |
| AGPSD1.6 | 1.6 | | | | | 1,030 |
| AGPSD1.7 | 1.7 | 20 | 43 | 0.5 | | 1,140 |
| AGPSD1.8 | 1.8 | | | | | 1,080 |
| AGPSD1.9 | 1.9 | 22 | 46 | | | 1,080 |
| AGPSD2.0 | 2.0 | | | | | 879 |
| AGPSD2.1 | 2.1 | 24 | 49 | 0.6 | | 1,300 |
| AGPSD2.2 | 2.2 | | | | | 1,300 |
| AGPSD2.3 | 2.3 | 27 | 53 | 0.7 | | 1,180 |
| AGPSD2.4 | 2.4 | | | | | 1,300 |
| AGPSD2.5 | 2.5 | 30 | 57 | | | 1,180 |
| AGPSD2.6 | 2.6 | | | | | 1,180 |
| AGPSD2.7 | 2.7 | | | 0.8 | | 1,180 |
| AGPSD2.8 | 2.8 | | | | | 1,240 |
| AGPSD2.9 | 2.9 | 33 | 61 | | | 1,180 |
| AGPSD3.0 | 3.0 | | | 0.9 | | 1,180 |
| AGPSD3.1 | 3.1 | | | | | 1,400 |
| AGPSD3.2 | 3.2 | 36 | 65 | | | 1,400 |
| AGPSD3.3 | 3.3 | | | 1.0 | | 1,400 |
| AGPSD3.4 | 3.4 | | | | | 1,400 |
| AGPSD3.5 | 3.5 | 39 | 70 | | | 1,400 |
| AGPSD3.6 | 3.6 | | | 1.1 | | 1,550 |
| AGPSD3.7 | 3.7 | | | | | 1,550 |
| AGPSD3.8 | 3.8 | | | | | 1,550 |
| AGPSD3.9 | 3.9 | | | | | 1,550 |
| AGPSD4.0 | 4.0 | 43 | 75 | 1.2 | ● | 1,550 |
| AGPSD4.1 | 4.1 | | | | | 1,740 |
| AGPSD4.2 | 4.2 | | | | | 1,740 |
| AGPSD4.3 | 4.3 | | | 1.3 | | 1,740 |
| AGPSD4.4 | 4.4 | | | | | 1,740 |
| AGPSD4.5 | 4.5 | 47 | 80 | | | 1,740 |
| AGPSD4.6 | 4.6 | | | 1.4 | | 1,960 |
| AGPSD4.7 | 4.7 | | | | | 1,960 |
| AGPSD4.8 | 4.8 | | | | | 1,960 |
| AGPSD4.9 | 4.9 | | | | | 1,960 |
| AGPSD5.0 | 5.0 | 52 | 86 | 1.5 | | 1,960 |
| AGPSD5.1 | 5.1 | | | | | 2,540 |
| AGPSD5.2 | 5.2 | | | | | 2,540 |
| AGPSD5.3 | 5.3 | | | 1.6 | | 2,540 |
| AGPSD5.4 | 5.4 | | | | | 2,540 |
| AGPSD5.5 | 5.5 | | | | | 2,540 |
| AGPSD5.6 | 5.6 | | | | | 2,560 |
| AGPSD5.7 | 5.7 | 57 | 93 | 1.7 | | 2,560 |
| AGPSD5.8 | 5.8 | | | | | 2,560 |
| AGPSD5.9 | 5.9 | | | | | 2,560 |
| AGPSD6.0 | 6.0 | | | 1.8 | | 2,560 |
| AGPSD6.1 | 6.1 | | | | | 2,750 |
| AGPSD6.2 | 6.2 | | | | | 2,750 |
| AGPSD6.3 | 6.3 | | | 1.9 | | 2,750 |
| AGPSD6.4 | 6.4 | 63 | 101 | | | 2,750 |
| AGPSD6.5 | 6.5 | | | | | 2,750 |
| AGPSD6.6 | 6.6 | | | | | 2,840 |
| AGPSD6.7 | 6.7 | | | 2.0 | | 2,840 |
| AGPSD6.8 | 6.8 | | | | | 2,840 |
| AGPSD6.9 | 6.9 | | | | | 2,840 |
| AGPSD7.0 | 7.0 | 69 | 109 | 2.1 | | 2,840 |
| AGPSD7.1 | 7.1 | | | | | 3,030 |

| 商品記号 Code | 直径 DC | 溝長 LCF | 全長 OAL | 先端 PL | 在庫 Stock | 参考価格(円) Price (¥) |
|--------------|----------|-----------|-----------|----------|-------------|----------------------|
| AGPSD7.2 | 7.2 | | | | | 3,030 |
| AGPSD7.3 | 7.3 | | | 2.2 | | 3,030 |
| AGPSD7.4 | 7.4 | 69 | 109 | | | 3,030 |
| AGPSD7.5 | 7.5 | | | | | 3,030 |
| AGPSD7.6 | 7.6 | | | 2.3 | | 3,220 |
| AGPSD7.7 | 7.7 | | | | | 3,220 |
| AGPSD7.8 | 7.8 | | | | | 3,220 |
| AGPSD7.9 | 7.9 | | | 2.4 | | 3,220 |
| AGPSD8.0 | 8.0 | | | | | 3,220 |
| AGPSD8.1 | 8.1 | 75 | 117 | | | 3,560 |
| AGPSD8.2 | 8.2 | | | | | 3,560 |
| AGPSD8.3 | 8.3 | | | 2.5 | | 3,560 |
| AGPSD8.4 | 8.4 | | | | | 3,560 |
| AGPSD8.5 | 8.5 | | | | | 3,560 |
| AGPSD8.6 | 8.6 | | | 2.6 | | 3,730 |
| AGPSD8.7 | 8.7 | | | | | 3,730 |
| AGPSD8.8 | 8.8 | | | | | 3,730 |
| AGPSD8.9 | 8.9 | | | 2.7 | | 3,730 |
| AGPSD9.0 | 9.0 | 81 | 125 | | | 3,730 |
| AGPSD9.1 | 9.1 | | | | | 4,320 |
| AGPSD9.2 | 9.2 | | | 2.8 | | 4,320 |
| AGPSD9.3 | 9.3 | | | | | 4,320 |
| AGPSD9.4 | 9.4 | | | 2.9 | | 4,320 |
| AGPSD9.5 | 9.5 | | | | | 4,320 |
| AGPSD9.6 | 9.6 | | | 3.0 | | 4,810 |
| AGPSD9.7 | 9.7 | | | | | 4,810 |
| AGPSD9.8 | 9.8 | | | | | 4,810 |
| AGPSD9.9 | 9.9 | | | 3.1 | | 5,300 |
| AGPSD10.0 | 10.0 | | | | | 4,810 |
| AGPSD10.1 | 10.1 | 87 | 133 | | ● | 5,940 |
| AGPSD10.2 | 10.2 | | | | | 5,670 |
| AGPSD10.3 | 10.3 | | | 3.2 | | 5,670 |
| AGPSD10.4 | 10.4 | | | | | 5,940 |
| AGPSD10.5 | 10.5 | | | | | 5,670 |
| AGPSD10.6 | 10.6 | | | 3.3 | | 6,610 |
| AGPSD10.7 | 10.7 | | | | | 6,610 |
| AGPSD10.8 | 10.8 | | | | | 6,610 |
| AGPSD10.9 | 10.9 | | | 3.4 | | 6,610 |
| AGPSD11.0 | 11.0 | | | | | 6,010 |
| AGPSD11.1 | 11.1 | | | 3.5 | | 7,290 |
| AGPSD11.2 | 11.2 | | | | | 7,290 |
| AGPSD11.3 | 11.3 | 94 | 142 | | | 7,290 |
| AGPSD11.4 | 11.4 | | | | | 7,290 |
| AGPSD11.5 | 11.5 | | | 3.6 | | 6,640 |
| AGPSD11.6 | 11.6 | | | | | 7,920 |
| AGPSD11.7 | 11.7 | | | | | 7,920 |
| AGPSD11.8 | 11.8 | | | 3.7 | | 7,920 |
| AGPSD11.9 | 11.9 | | | | | 7,920 |
| AGPSD12.0 | 12.0 | | | | | 7,200 |
| AGPSD12.1 | 12.1 | | | 3.8 | | 10,300 |
| AGPSD12.2 | 12.2 | | | | | 10,300 |
| AGPSD12.3 | 12.3 | | | 3.9 | | 10,300 |
| AGPSD12.4 | 12.4 | 101 | 151 | | | 10,300 |
| AGPSD12.5 | 12.5 | | | | | 9,340 |
| AGPSD12.6 | 12.6 | | | | | 11,200 |
| AGPSD12.7 | 12.7 | | | | | 11,200 |
| AGPSD12.8 | 12.8 | | | | | 11,200 |
| AGPSD12.9 | 12.9 | | | | | 11,200 |
| AGPSD13.0 | 13.0 | | | | | 9,980 |

※ 1 本包装 (2.0mm 未満は 10 本包装)
 参考価格は 1 本あたりの価格です。
 ※ Sold one per package (10 per package if below 2.0mm)
 Price is for one drill bit.

新商品

超硬ドリル

ハイスドリル

タップ

超硬
エンドミル

ハイス
エンドミル

切断工具

バック・
セット商品
その他

精密工具

技術資料
索引