


# Product models & dimensions


## Plug

- AP-P(F)

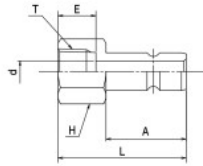


Model	L (MM)	A (MM)	d (MM)	E (MM)	T	H (MM)	W (g)
AP - 10PF	27	16.9	4.5	8	Rc 1/8	HEX. 14	17
AP - 12PF	32	16.9	4.5	13	Rc 1/4	HEX. 16	20

- AP-P(M)

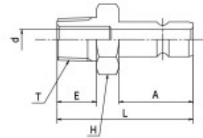


Model	L (MM)	A (MM)	d (MM)	E (MM)	T	H (MM)	W (g)
AP - 10PM	31	16.9	4.5	9	R 1/8	HEX. 14	10
AP - 12PM	33.5	16.9	4.5	13	R 1/4	HEX. 14	11

- AP-P(H)

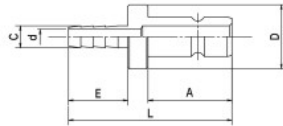


Model	L (MM)	A (MM)	d (MM)	C (MM)	E (MM)	D (MM)	W (g)
AP - 10PH	33	16.9	3	4.5	12	13	10
AP - 12PH	40	16.9	4.5	6.5	16	13	11

- APV-S(HF)

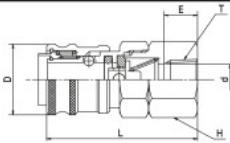


Model	L (MM)	D (MM)	E (MM)	T	H (MM)	d (MM)	W (g)
APV - 10SF	43	17	8	Rc 1/8	HEX. 16	7.5	45
APV - 12SF	43.1	17	13	Rc 1/4	HEX. 16	7.5	41

- APVC-P(F)

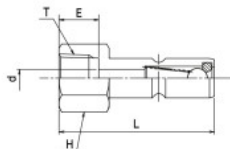


Model	L (MM)	d (MM)	E (MM)	T	H (MM)	W (g)
APVC - 10PF	32	4.5	9	Rc 1/8	HEX. 14	11
APVC - 12PF	36	4.5	13	Rc 1/4	HEX. 16	22

- APVC-P(M)

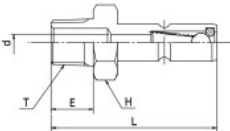

Model	L (MM)	d (MM)	E (MM)	T	H (MM)	W (g)
APVC - 10PM	35.2	4.5	9	R 1/8	HEX. 14	16
APVC - 12PM	39.2	4.5	13	R 1/4	HEX. 16	21

 - APVC-P(H)




Model	L (MM)	D (MM)	E (MM)	C (MM)	d (MM)	W (g)
APVC - 10PH	37.2	13	12	4.5	3	11
APVC - 12PH	41.2	13	16	6.5	4.5	12

## Socket


### AP Type

- AP-S(F)

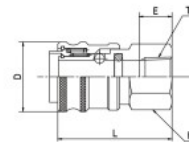


Model	L (MM)	D (MM)	E (MM)	T	H (MM)	W (g)
AP - 10SF	28	17	8	Rc 1/8	HEX. 14	25
AP - 12SF	33	17	13	Rc 1/4	HEX. 16	32

- AP-S(M)

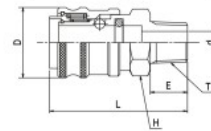

Model	L (MM)	D (MM)	E (MM)	T	H (MM)	d (MM)	W (g)
AP - 10SM	31	17	9	R 1/8	HEX. 14	5.5	27
AP - 12SM	35	17	13	R 1/4	HEX. 14	7.5	29


- APV-S(M)

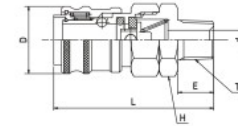

Model	L (MM)	D (MM)	E (MM)	T	H (MM)	d (MM)	W (g)
APV - 10SM	40.2	17	9	Rc 1/8	HEX. 16	5	45
APV - 12SM	44.2	17	13	Rc 1/4	HEX. 16	7.5	46

### APV Type


- APV-S(H)

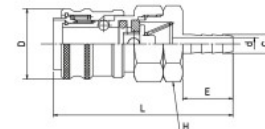

Model	L (MM)	D (MM)	E (MM)	C (MM)	H (MM)	d (MM)	W (g)
APV - 10SH	40.5	17	12	4.5	HEX. 16	3	47
APV - 12SH	49.5	17	19	6.5	HEX. 16	4.5	45


### APVC Type

- APVC-S(F)

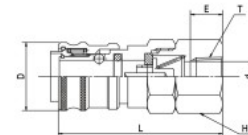


Model	L (MM)	D (MM)	E (MM)	T	H (MM)	d (MM)	W (g)
APVC - 10SF	43	17	8	R 1/8	HEX. 16	7.5	40
APVC - 12SF	43	17	13	R 1/4	HEX. 16	7.5	44

- APVC-S(M)

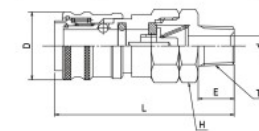

Model	L (MM)	D (MM)	E (MM)	T	H (MM)	d (MM)	W (g)
APVC - 10SM	44.7	17	9	R 1/8	HEX. 16	5	40
APVC - 12SM	47.7	17	13	R 1/4	HEX. 16	7.5	44

 - APVC-S(H)



Model	L (MM)	D (MM)	E (MM)	C (MM)	H (MM)	d (MM)	W (g)
APVC - 10SH	47.7	17	12	4.5	HEX. 16	3	32
APVC - 12SH	54.7	17	19	6.5	HEX. 16	4.5	39