

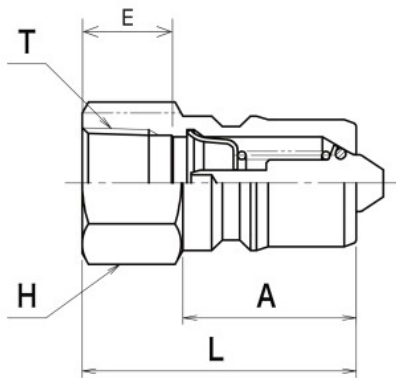


Product models & dimensions

Plug

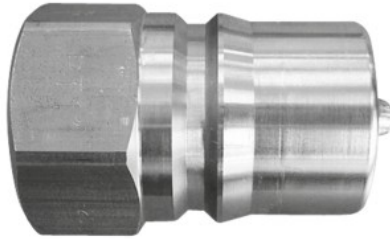

Socket

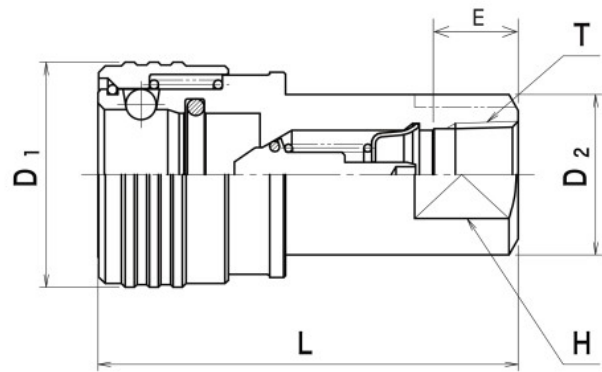

Model	L (MM)	A (MM)	E (MM)	T	H (MM)	W (g)
SUP 150	29	19	11	Rc 1/8	HEX. 14	18
SUP 250	35.5	22	12.4	Rc 1/4	HEX. 17	35
SUP 350	39.9	25.2	13	Rc 3/8	HEX. 21	60
SUP 450	44	28	15	Rc 1/2	HEX. 29	115
SUP 650	52	36.5	19	Rc 3/4	HEX. 35	191
SUP 800	62	40	20	Rc 1	HEX. 41	330

Model	L (MM)	A (MM)	E (MM)	T	H (MM)	W (g)
SUS 150	48	24	11	Rc 1/8	Face width 14	85
SUS 250	58	28	12.4	Rc 1/4	Face width 17	137
SUS 350	65	35	13	Rc 3/8	Face width 21	207
SUS 450	71.7	45	15	Rc 1/2	Face width 29	441
SUS 650	88	55	19	Rc 3/4	Face width 39	730
SUS 800	102	64	20	Rc 1	Face width 41	1070

Larger sizes are custom made on request, please contact local dealer.

Ordering information

SU **S** **250** - **P**

① ② ③

① Type

S	Socket
P	Plug

② Size

150	1/8
250	1/4
350	3/8
450	1/2
650	3/4
800	1

③ Seal material

N	Nitrile butadiene rubber
V	Fluorine rubber
E	Ethylene propylene rubber
P	Perfluoro elastomer
K	Kalretz