 



NK-FJ-C Female Union Type

DN: 6mm(1/8") ~ 50mm(2")
Length: 250mm ~ 10M

NK-FJS-C/Straight Tube



 NK-FJP-C/ Spiral Corrugated Tube



NK-FJS-C/Straight Tube

① Socket	Carbon Steel, Stainless Steel
② Nut	Stainless Steel
③ Sleeve	Stainless Steel
④ Ring	Stainless Steel
⑤ Tube	PTFE
⑥ Braid	Stainless Steel
⑦ Guard Spring	Stainless Steel




NK-FJP-C/ Spiral Corrugated Tube

① Socket	Carbon Steel, Stainless Steel
② Nut	Carbon Steel, Stainless Steel
③ Sleeve	Stainless Steel
④ Ring	Stainless Steel
⑤ Tube	PTFE
⑥ Braid	Stainless Steel


NK-FJ-S Sanitary Flange Type

DN: 1.0S ~ 2.0S
Length: 250mm ~ 10M

NK-FJS-S/Straight Tube

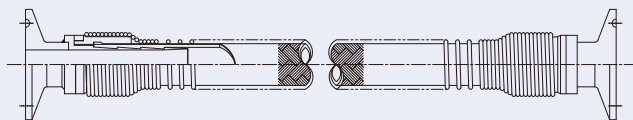

NK-FJP-S/Spiral Tube

 

NK-FJS-S/Straight Tube

① Sanitary Flange	Stainless Steel
② Sleeve	Stainless Steel
③ Ring	Stainless Steel
④ Tube	PTFE
⑤ Braid	Stainless Steel
⑥ Guard Spring	Stainless Steel



NK-FJP-S/Spiral Tube

① Sanitary Flange	Stainless Steel
② Ring	Stainless Steel
③ Tube	PTFE
④ Braid	Stainless Steel

Threaded Type Flexible Hose

F1

Flange Type Flexible Hose

F2

Fire Law Flexible Hose

F3

Quick Connection Flexible Hose

F4

Flexible Hose for Vacuums

F5

Flexible Hose with Fluororesin

F6

Other Flexible Hose

F7