


NJC Series Shell Size 16

NJC

16

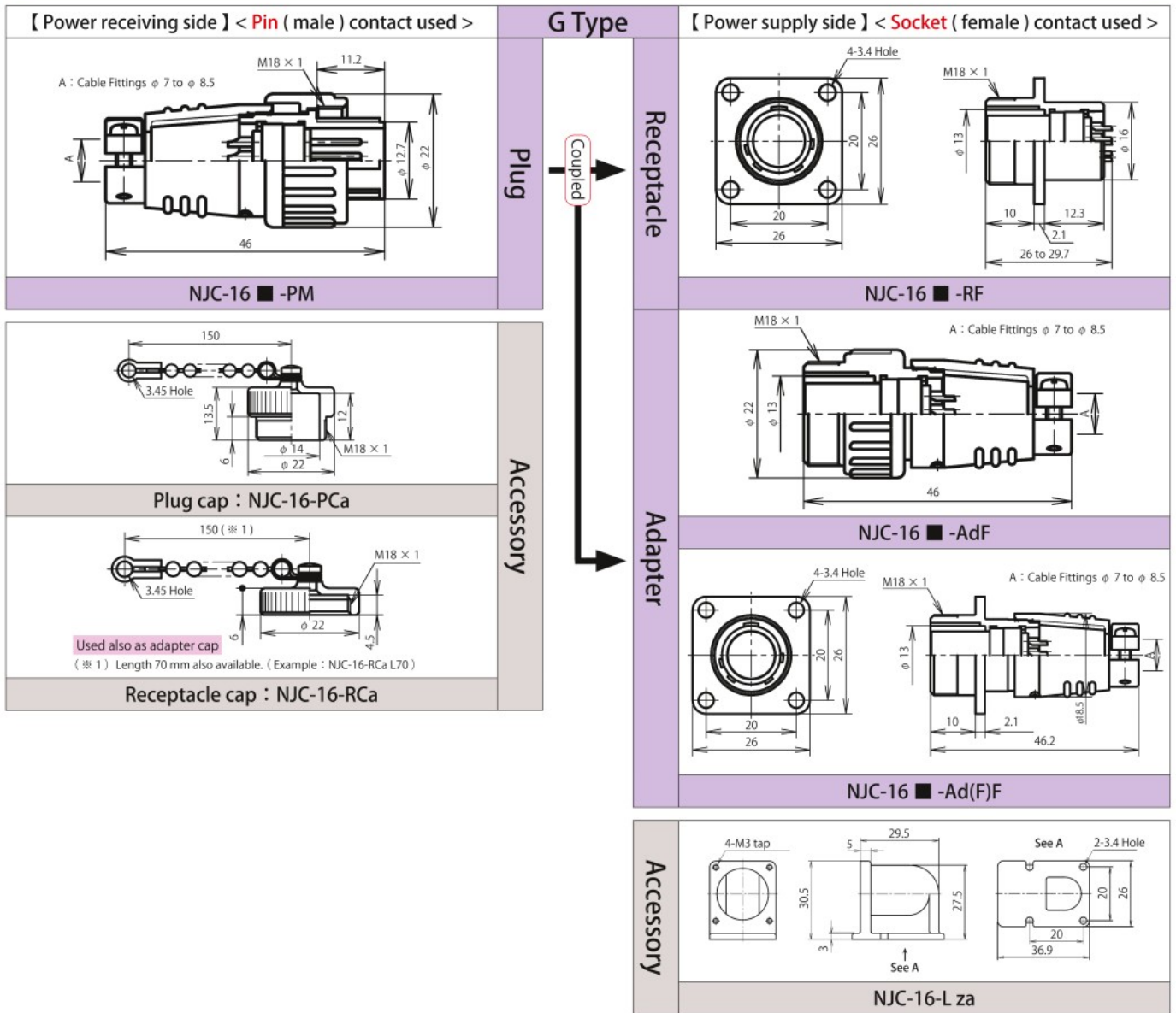

■ indicates the number of contacts.
 The conductor cross sectional area is less than the following value. However, for safety standard certified products, use a cable having a value shown on p.127.

Shell size	Number of Contacts	3	5	8
16	Contact arrangement <When viewed from the pin (male) contact coupling side>			
	Safety standard (Note-1)	UL·CSA		—
	Rating (Allowable current for signals)	125V		—
	Withstand voltage (V r.m.s.)	1,500	1,000	500
	Wire size (mm ²)	1.25	0.5	0.3
	Remarks	—		For signals

[] : Gold plating contact

Note-1 : Specified separately. *Specified as a set of UL and CSA*. For safety standards, see p.127.