


TC Type

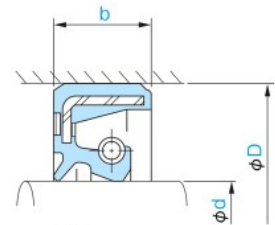

TC type

- The sectional view on the right shows the typical profile of the seal type.
- Please refer to page 25 for the respective advantages and disadvantages of Types B and C.
- Check the guide to allowable operating conditions on pages 10 and 11 for relevant information on the seal selected before use.
- If there is an “※” at the end of the part number, as this indicates that an SUS spring specification is available, we ask that you refer to the introduction on SUS spring specifications on page 152.

■ When ordering, please indicate the NOK part number and the relevant dimensions.
Order Example NOK Part Number: AE 0090 A0
 Type: TC, Shaft diameter: 7, Outside diameter: 20, Width: 7

14

TC type

Dimensions			Part Number			
Shaft diameter d	Outside diameter D	Width b	Nitrile (NBR) <small>shaft diameter of 150 mm or less: A727 shaft diameter over 150 mm: A941</small>	Acrylic (ACM) T303	Silicon (VMQ) S728	Fluorocarbon (FKM) F585
7	20	7	AE 0090 A0	—	—	—
8	22	7	AE 0158 A4	—	AE 0158 A2	AE 0158 F2
8	25	8	AE 0164 E0	—	—	—
8	34	8	AE 0169 E0	—	—	—
9	22	7	AE 0205 A0	AE 0205 E0	—	—
9	28	8	AE 0210 E0	—	—	—
10	20	7	AE 0260 J0 ※	—	—	—
10	25	7	AE 0279 A6 ※	—	AE 0279 A2	—
10	28	8	AE 0285 E0	—	—	—
11	25	7	AE 0311 E0	—	—	—
11	30	10	AE 0315 E0	—	—	—
12	22	7	AE 0371 E0	AE 0371 L0	—	—
12	23	8	AE 0375 E0	—	—	—
12	25	7	AE 0382 A0 ※	—	AE 0382 A2	AE 0382 K1
12	28	7	AE 0387 E0 ※	—	—	—
12	30	9	AE 0393 E0	—	—	—
12	32	7	AE 0399 E1 ※	—	—	—
13	25	7	AE 0473 F0	—	—	—
13	28	7	AE 0478 A0	—	—	—
13	30	8	AE 0483 G0	—	—	—
14	25	7	AE 0519 E0 ※	—	—	—
14	28	7	AE 0526 A0 ※	—	—	AE 0526 F0
14	28	11	AE 0529 E0	—	—	—
14	32	9	AE 0536 E0	—	—	—
15	25	7	AE 0588 K1	—	—	—
15	30	7	AE 0598 A0	AE 0598 A1	—	—
15	30	10	AE 0600 E0	—	—	—
15	32	9	AE 0604 E0	—	—	—
15	35	7	AE 0610 F0	—	—	—
15	35	8	AE 0611 E1 ※	—	—	—
16	26	7	AE 0678 F1	—	—	—
16	28	7	AE 0685 G0	—	—	—
16	30	7	AE 0687 A0 ※	AE 0687 A1	AE 0687 A7	—
16	35	9	AE 0698 E0	—	—	—
17	30	7	AE 0743 E0	—	—	—
17	30	8	AE 0745 E8	—	—	—
17	32	7	AE 0750 E0	—	—	—
17	32	8	AE 0751 H6	—	—	—
17	35	7	AE 0759 E0	—	—	—
17	35	8	AE 0760 H5	—	AE 0760 A2	AE 0760 F0
17	35	10	AE 0761 F0	—	—	—
17	38	7	AE 0768 E0	—	—	—
17	40	9	AE 0772 E1	—	—	—
18	30	8	AE 0817 E0	—	—	—
18	32	7	AE 0823 E0 ※	—	—	—