










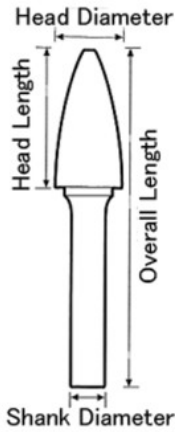

TCB Tungsten Carbide Burr (Tree)

Product code : TCB



												
Head Diameter (mm)	Head Length (mm)	Shank Diameter (mm)	Overall Length (mm)	s cut	k cut	d cut	d-max cut	c cut	alu cut	s-inx cut	d-steel cut	rv cut
				Spiral shaped burr provides smooth surface.	Designed to produce smooth finish on hard materials.	The most popular cutting style provides aggressive grinding performance.	Ideal for tough applications.	Small teeth works on high tensile steel.	Designed for aluminum and non ferrous metals.	cutting force higher than conventional product "s-cut".	cutting force higher than conventional products "d-cut" and "d-max cut".	cut shape with strong cutting force and durability.
3	6	3	38	●	—	●	—	—	—	—	—	—
3	10		38	●	—	●	—	—	—	—	—	—
3	13		38	●	●	●	—	—	—	—	—	—
6	13		45	●	—	●	—	—	—	—	—	—
6	19	6	50	●	●	●	—	●	—	●	●	●
8	19		65	—	●	●	—	—	—	●	●	●
10	19		65	●	●	●	—	●	—	●	●	●
12	19		65	●	—	●	—	—	—	—	—	—
12	25		70	●	●	●	●	●	—	●	●	●
16	25		70	●	—	●	—	—	—	—	—	●
12	25	8	70	●	—	●	—	—	—	—	—	—
16	25		70	●	—	●	—	—	—	—	—	—
Head Diameter (mm)	Head Length (mm)	Shank Diameter (mm)	Overall Length (mm)	s cut	k cut	d cut	d-max cut	c cut	alu cut	s-inx cut	d-steel cut	rv cut

Close this window

[▲ To TOP](#)