


Coupler

PushOne™ type

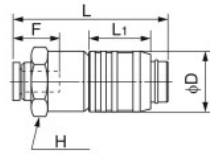


Product number	Applicable tubing outer diameter (mm)	L (mm)	L ₁ (mm)	F Tubing insertion length (mm)	H Width across flat (mm)	D (mm)	Weight (g)
101C4-6E	6	49.3	19.5	15	19.0	19.0	62.0
101C4-8E	8	50.9	19.5	16	19.0	19.0	62.0
101C4-10E	10	53.9	19.5	19	19.0	19.0	64.5

Internal thread type

Brass type



Stainless type

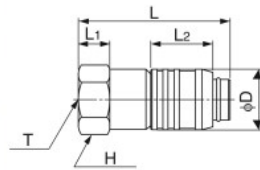

Product number	T Thread size (RC)	L (mm)	L ₁ (mm)	L ₂ (mm)	H Width across flat (mm)	D (mm)	Weight (g)
101C4-2F	RC1/8	48.0	10.0	19.5	19.0	19.0	67.5
101C4-4F	RC1/4	48.0	10.0	19.5	19.0	19.0	60.5
* S101C4-2F	RC1/8	48.0	10.0	19.5	19.0	19.0	67.5
* S101C4-4F	RC1/4	48.0	10.0	19.5	19.0	19.0	60.5


*Made to order

External thread type

Brass type



Stainless type

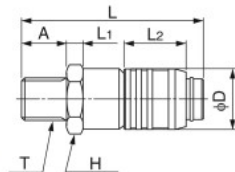


Product number	T Thread size (R)	L (mm)	A (mm)	L ₁ (mm)	L ₂ (mm)	H Width across flat (mm)	D (mm)	Weight (g)
101C4-2M	R1/8	53.5	10.0	5.5	19.5	19.0	19.0	59.0
101C4-4M	R1/4	57.5	14.0	5.5	19.5	19.0	19.0	64.0
* S101C4-2M	R1/8	53.5	10.0	5.5	19.5	19.0	19.0	59.0
* S101C4-4M	R1/4	57.5	14.0	5.5	19.5	19.0	19.0	64.0

*Made to order

N2-1-1/4 type



Product number : 101C4-4T

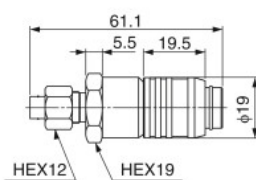


Weight : 64.0g

Nylon coil tubing S1/4 type



Product number : 101C4-4S

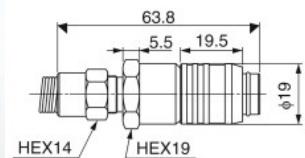


Weight : 78.5g

φ8 hose type



Product number : 101C4-4H

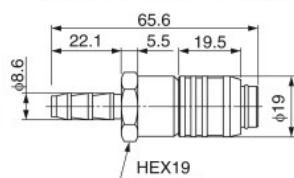

Weight : 63.5g

Tubing

Clean tubing

Processed tubing

PushOne fitting

QuickSeal fitting

Clean fitting/Chemifit

Bamboo-shoot fitting

Control switch/Detachable series

Jig/Tool/Accessory

Technical information

Reference