

Brother ie3 MMD Series



Features Electrocoat Paint

- Helical (parallel) and Hypoid (right angle) gear type motors
- Pre-assembled, motor & gear
- Slip fit "O" ring design for mounting in any direction

Single or Three-Phase

Brother ie3 Mid Series Helical / Hypoid Gear Type



Type	Induction
Output Power	400 W (1/2 HP)~3 HP
Speed Range (r/min)	90~3600 (3~120 Hz)
Options	Terminal Box / Electromagnetic Brake
	Stainless Steel Shafts
Gear Types	Parallel, Right Angle Hollow or Solid
Starting Pricing (Motor+Gear)	\$626.00

FPW Series IP67 Rated



- Conforms to IEC Standard IP67
- Pre-assembled, Motor & Gear
- Water Tight and Dust Resistant


Single-Phase / Three-Phase

FPW Series



Type	Induction
Output Power	25 W (1/30 HP)~90 W (1/8 HP)
Frame Size	80 mm (3.15 in.)~104 mm (4.09 in.)
Gear Types	Parallel
Single-Phase (VAC)	110-115 / 220-230
Three-Phase (VAC)	220-230
Starting Pricing (Motor+Gear)	\$320.00

Torque Motors Torque Control

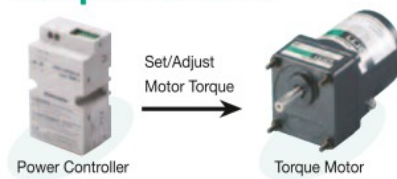

TMP-1 Power Controller
(sold separately)
List Price: \$135.00

Single-Phase

WK Series




Type	Torque Motor
Output Power	3 W (1/250 HP)~23 W (1/38 HP)
Frame Size	60 mm (2.36 in.)~90 mm (3.54 in.)
Gear Types	Parallel
Single-Phase	110-115 / 220-230
Starting Pricing (Motor+Gear)	\$200.00

Applications


Belt Conveyor



Tension Control

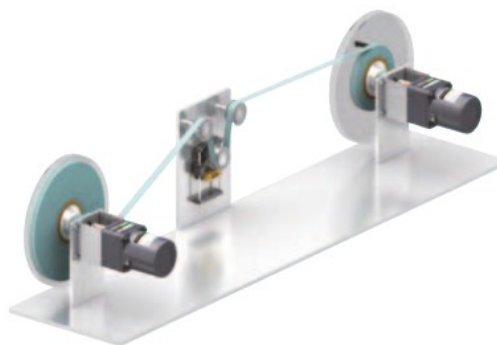

Pinch Conveyor

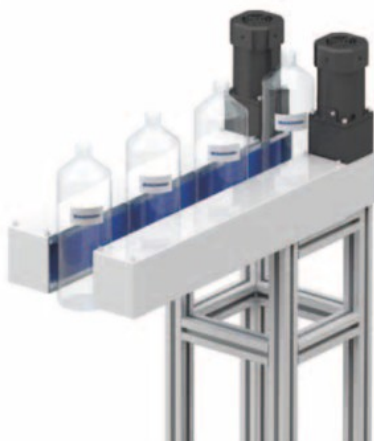

Packing System

