


G-LIST No TH1033

非鉄合金用 FOR NON-FERROUS METALS

B-NRT

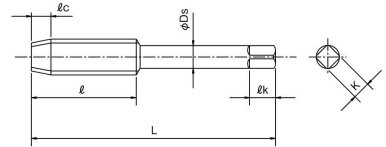

●マークの説明はP.2をご覧ください。
See page 2 for explanation of icons.

単位:mm Unit:mm

ツールNo. EDP No.	呼び Thread Size	精度表記 Grade	精度 TAP Unit	食付 ℓc	全長 L	ねじ長 ℓ	首下長 ℓn	シャンク径 Ds	突出し センタ External Centre	在庫 Stock	重量 Weight	標準価格 (Yen)
21390	M 1 x0.25	STD	RH4	4P	30	7	-	3	有	A	3	2,260
21391		STD	RH4	2P								2,260
21392		STD+1	RH5	4P								2,440
21393		STD+1	RH5	2P								2,440
21396	M 1.1 x0.25	STD	RH4	4P	32	8	-	3	有	D	3	2,440
21397		STD	RH4	2P								2,440
21398		STD+1	RH5	4P								2,440
21399		STD+1	RH5	2P								2,440
21402	M 1.2 x0.25	STD	RH4	4P	32	8	-	3	有	A	3	2,070
21403		STD	RH4	2P								2,070
21404		STD+1	RH5	4P								2,230
21405		STD+1	RH5	2P								2,230
21408	M 1.4 x0.3	STD	RH4	4P	34	9	-	3	有	A	3	1,840
21409		STD	RH4	2P								1,840
21410		STD+1	RH5	4P								1,980
21411		STD+1	RH5	2P								1,980
21414	M 1.6 x0.35	STD	RH4	4P	36	10	-	3	有	D	3	2,070
21415		STD	RH4	2P								2,070
21416		STD+1	RH5	4P								2,070
21417		STD+1	RH5	2P								2,070
21420	M 1.7 x0.35	STD	RH4	4P	36	11	-	3	有	A	3	1,700
21421		STD	RH4	2P								1,700
21422		STD+1	RH5	4P								1,840
21423		STD+1	RH5	2P								1,840
21424	M 1.8 x0.35	STD+2	RH6	4P	36	11	-	3	有	D	3	1,840
21425		STD+2	RH6	2P								1,840
21426		STD	RH4	4P								2,070
21427		STD	RH4	2P								2,070
21428	M 1.8 x0.35	STD+1	RH5	4P	36	11	-	3	有	A	3	2,070
21429		STD+1	RH5	2P								2,070
21432		STD	RH4	4P								1,490
21433		STD	RH4	2P								1,490
21434	M 2 x0.4	STD+1	RH5	4P	40	12	-	3	有	A	3	1,490
21435		STD+1	RH5	2P								1,490
21436		STD+2	RH6	4P								1,490
21437		STD+2	RH6	2P								1,490
21438	M 2 x0.25	STD	RH4	4P	40	12	-	3	有	A	3	2,580
21439		STD	RH4	2P								2,580
21440		STD+1	RH5	4P								2,580
21441		STD+1	RH5	2P								2,580
21444	M 2.2 x0.45	STD	RH4	4P	42	13	-	3	有	D	4	1,680
21445		STD	RH4	2P								1,680
21446		STD+1	RH5	4P								1,680
21447		STD+1	RH5	2P								1,680
21456	M 2.3 x0.4	STD	RH4	4P	42	13	-	3	有	A	3	1,400
21457		STD	RH4	2P								1,400
21458		STD+1	RH5	4P								1,510
21459		STD+1	RH5	2P								1,510
21460	M 2.5 x0.45	STD+2	RH6	4P	44	14	-	3	有	D	4	1,510
21461		STD+2	RH6	2P								1,510
21468		STD	RH4	4P								1,400
21469		STD	RH4	2P								1,400
21470	M 2.5 x0.45	STD+1	RH5	4P	44	14	-	3	有	A	4	1,510
21471		STD+1	RH5	2P								1,510
21472		STD+2	RH6	4P								1,510
21473		STD+2	RH6	2P								1,510
21480	M 2.6 x0.45	STD	RH4	4P	44	14	-	3	有	A	3	1,320

ツールNo. EDP No.	呼び Thread Size	精度表記 Grade	精度 TAP Unit	食付 ℓc	全長 L	ねじ長 ℓ	首下長 ℓn	シャンク径 Ds	突出し センタ External Centre	在庫 Stock	重量 Weight	標準価格 (Yen)
21481	M 2.6 x0.45	STD	RH4	2P	44	14	-	3	有	A	3	1,320
21482		STD+1	RH5	4P								1,320
21483		STD+2	RH6	2P								1,320
21484		STD+2	RH6	2P								1,320
21485	M 3 x0.5	STD-2	RH3	4P	46	9	18	4	有	D	5	1,350
12710		STD-2	RH3	2P								1,350
12711		STD	RH5	4P								1,250
12714		STD	RH5	2P								1,250
12715	M 3.5 x0.6	STD-3	RH8	4P	48	9	18	4	有	D	5	1,350
12718		STD-3	RH8	2P								1,350
12719		STD-2	RH3	4P								1,350
12720		STD-2	RH3	2P								1,350
12721	M 4 x0.7	STD	RH5	4P	52	10	20	5	有	A	8	1,400
12724		STD	RH5	2P								1,400
12725		STD-2	RH4	4P								1,400
12730		STD-2	RH4	2P								1,400
12731	M 4 x0.7	STD	RH6	4P	52	10	20	5	有	A	8	1,300
12734		STD	RH6	2P								1,300
12735		STD+3	RH9	4P								1,400
12738		STD+3	RH9	2P								1,400
12739	M 5 x0.8	STD-2	RH4	4P	60	11	22	5.5	有	D	11	1,500
12740		STD-2	RH4	2P								1,500
12741		STD	RH6	4P								1,390
12744		STD	RH6	2P								1,390
12745	M 6 x1	STD+3	RH9	4P	62	12	24	6	有	A	11	1,500
12748		STD+3	RH9	2P								1,500
12749		STD-3	RH4	4P								1,630
12750		STD-3	RH4	2P								1,630
12751	M 6 x1	STD	RH7	4P	65	13	26	6.2	有	D	13	1,510
12755		STD	RH7	2P								1,510
12757		STD+2	RH9	4P								1,630
12760		STD+2	RH9	2P								1,630
12761	M 7 x1	STD	RH6	4P	70	18	-	6.2	有	A	20	2,280
12766		STD	RH6	2P								
12772	M 8 x1.25	STD-2	RH5	4P	70	18	-	6.2	有	A	20	2,280
12773		STD-2	RH5	2P								2,280
12776		STD	RH7	4P								2,280
12777		STD	RH7	2P								2,280
12778	M 8 x1	STD+1	RH8	4P	70	18	-	6.2	有	D	20	2,440
12779		STD+1	RH8	2P								2,440
12784		STD-3	RH4	4P								2,820
12785		STD-3	RH4	2P								2,820
12786	M 8 x1	STD	RH7	4P	70	18	-	6.2	有	D	20	2,820
12787		STD	RH7	2P								2,820
12790		STD	RH7	4P								2,820
12791		STD	RH7	2P								2,820
12804	M10 x1.5	STD-2	RH5	4P	75	19	-	7	有	A	30	3,080
12805		STD-2	RH5	2P								3,080
12808		STD	RH7	4P								2,910
12809		STD	RH7	2P								2,910
12812	M10 x1.25	STD+2	RH9	4P	75	19	-	7	有	A	30	3,080
12813		STD+2	RH9	2P								3,080
12818		STD-2	RH5	4P								3,080
12819		STD-2	RH5	2P								3,080
12822	M10 x1.25	STD	RH7	4P	75	19	-	7	有	A	30	2,910
12823		STD	RH7	2P								2,910
12824		STD+1	RH8	4P								3,080
12825		STD+1	RH8	2P								3,080