

7


LB series (Inside measuring of ID and groove widths)



LB-1
Graduation: 0.1mm
Range: 10~90mm
Throat depth: 125mm



LB-2
Graduation: 0.1mm
Range: 10~90mm
※Throat depth: 180mm
※See page 103

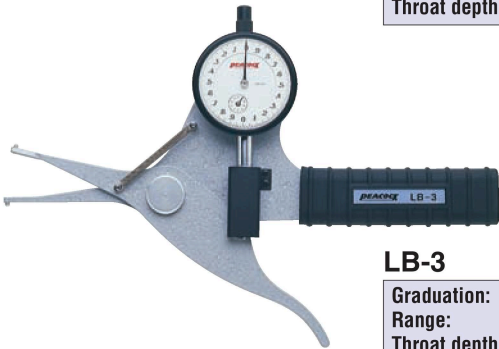

LB-3
Graduation: 0.01mm
Range: 10~30mm
Throat depth: 50mm



LB-4
Graduation: 0.01mm
Range: 10~30mm
Throat depth: 100mm



LB-5
Graduation: 0.01mm
Range: 20~40mm
Throat depth: 150mm



LB-6
Graduation: 0.01mm
Range: 30~50mm
Throat depth: 80mm



LB-8
Graduation: 0.01mm
Range: 100~120mm
Throat depth: 90mm




LB-9
Graduation: 0.01mm
Range: 20~40mm
Throat depth: 130mm



Dial Calipers


Dimensions for contact point

(LB-1 · 2 · 3 · 4 · 5 · 6 · 7, LH-2)

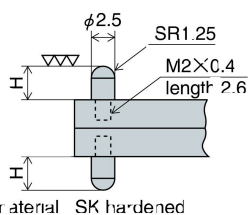


Material: SK hardened
※ H:mm (height of contact point)
3, 4, 5, 6, 7, 8, 9, 10mm type are available as options. Order pair as 1 set (2pcs).

(LB-7V)

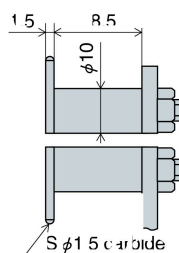

(LB-7S)

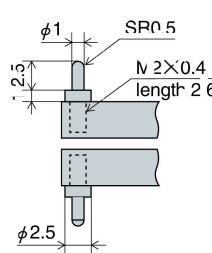

(LA-14 · LB-14)

