


VFU Union Type



RoHS compliant

Copper alloy free
Selectable

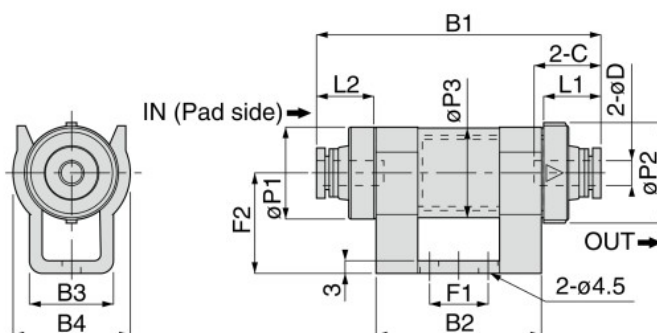

Unit : mm

Model code	Tube O.D. øD	B1	B2	B3	B4	L1	L2	øP1	øP2	øP3	C	F1	F2	Filter area (cm ²)	Weight (g)	CAD file name
VFU2-44P-□	4	58	33	18	24	11.9	11.9	18.2	20	17.5	14.9	10	20	7.5	18	VFU2-44P
VFU2-66P-□	6	60				13	13				16				19	VFU2-66P
VFU3-66P-□	6	67.7	39.5	20	28	13.5	13.8	22.1	24	21.5	16.5	14	24	12.5	27	VFU3-66P
VFU3-88P-□	8	70.1				14.9	14.7				17.9				29	VFU3-88P
VFU3-1010P-□	10	72.7				16.2	16				19.2				32	VFU3-1010P

※ 1. Fill in □ in Model code with "NH" for no fixing holder.

※ 2. Add "-S3" at the end of model code for "Copper alloy free".

Replacement of Element

