




Hexagonal Hole Type Straight

RoHS compliant

OP.
P.754

CAD

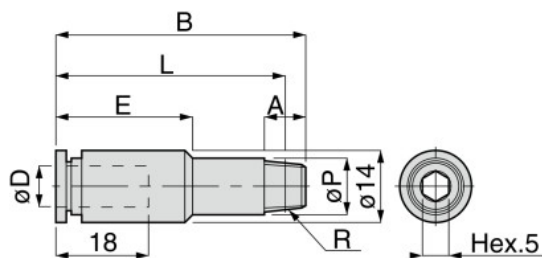

Unit : mm

Model code	Tube O.D. øD	R	A	B	L	øP	E	Weight (g)	Orifice dia.	CAD file name
POC8-01-L40	8	R1/8	8	48.5	44.5	11	26.5	28	5.3	TFSL-001
POC8-01-L50				58.5	54.5			34		
POC8-01-L60				68.5	64.5			59		
POC8-01-L70				78.5	74.5			45		
POC8-01-L80				88.5	84.5			51		
POC8-01-L90				98.5	94.5			56		
POC8-01-L100				108.5	104.5			62		
POC8-01-L110				118.5	114.5			68		
POC8-02-L50		R1/4	11	58.5	52.5	-	-	47		
POC8-02-L60				68.5	62.5			58		
POC8-02-L70				78.5	72.5			68		
POC8-02-L80				88.5	82.5			78		

※ . "L" is a reference value for height dimension after tightening thread.