
 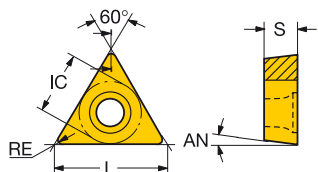
 
 


CoroTurn® 107 insert for turning

Triangular




				P										M					K				N		S												
				ISO CODE	1515	1525	4205	4235	4315	4325	5015	GC30	1115	1125	2015	2025	2035	235	GC15	3005	3205	3210	3215	GC30	H3A	1125	H10	H3A	1105	1115	1125	GC15	H3A	ANSI CODE			
	05	1/8	TCEX 05 01 00L-F											☆																				TCEX 1(1)00L-F			
			TCEX 05 01 00R-F												☆																			TCEX 1(1)00R-F			
			TCEX 05 01 01L-F												☆											☆									TCEX 1(1)03L-F		
			TCEX 05 01 01R-F												☆											☆									TCEX 1(1)03R-F		
	06	5/32	TCEX 06 T1 00L-F											☆																☆	☆				TCEX 1.2(1.2)00L-F		
			TCEX 06 T1 00R-F												☆														☆	☆					TCEX 1.2(1.2)00R-F		
			TCEX 06 T1 01L-F												☆														☆	☆					TCEX 1.2(1.2)03L-F		
			TCEX 06 T1 01R-F												☆														☆	☆					TCEX 1.2(1.2)03R-F		
			TCEX 06 T1 02L-F											☆															☆	☆						TCEX 1.2(1.2)0L-F	
			TCEX 09 02 00L-F								☆				☆														☆	☆						TCEX 1.8(1.5)00L-F	
			TCEX 09 02 00R-F								☆				☆														☆	☆						TCEX 1.8(1.5)00R-F	
			TCEX 09 02 01L-F								☆				☆														☆	☆						TCEX 1.8(1.5)03L-F	
			TCEX 09 02 01R-F							☆				☆															☆	☆						TCEX 1.8(1.5)03R-F	
			TCEX 09 02 02L-F							☆				☆															☆	☆						TCEX 1.8(1.5)0L-F	
			TCEX 11 03 00L-F								☆				☆														☆	☆						TCEX 22(00)L-F	
			TCEX 11 03 00R-F								☆				☆														☆	☆						TCEX 22(00)R-F	
			TCEX 11 03 01L-F							☆				☆															☆	☆						TCEX 22(03)L-F	
			TCEX 11 03 01R-F							☆				☆															☆	☆						TCEX 22(03)R-F	
			TCEX 11 03 02L-F							☆				☆															☆	☆						TCEX 220L-F	
																														☆	☆						
		06	5/32	TCGT 06 T1 02L-K	☆									☆	☆																☆	☆				TCGT 1.2(1.2)0L-K	
				TCGT 06 T1 02R-K	☆											☆	☆														☆	☆					TCGT 1.2(1.2)0R-K
				TCGT 06 T1 04L-K	☆											☆	☆														☆	☆					TCGT 1.2(1.2)1L-K
				TCGT 06 T1 04R-K	☆											☆	☆														☆	☆					TCGT 1.2(1.2)1R-K
09		7/32	TCGT 09 02 02L-K	☆	☆						☆		☆	☆																☆	☆					TCGT 1.8(1.5)0L-K	
			TCGT 09 02 02R-K	☆	☆							☆		☆	☆															☆	☆					TCGT 1.8(1.5)0R-K	
			TCGT 09 02 04L-K	☆	☆							☆		☆	☆															☆	☆					TCGT 1.8(1.5)1L-K	
			TCGT 09 02 04R-K	☆								☆		☆	☆															☆	☆					TCGT 1.8(1.5)1R-K	
11		1/4	TCGT 11 02 02L-K		☆						☆		☆	☆																☆						TCGT 2(1.5)0L-K	
			TCGT 11 02 02R-K											☆	☆																☆					TCGT 2(1.5)0R-K	
			TCGT 11 02 04L-K		☆						☆		☆	☆																☆		☆				TCGT 2(1.5)1L-K	
			TCGT 11 02 04R-K											☆	☆												☆	☆		☆	☆		☆			TCGT 2(1.5)1R-K	
		TCGT 11 03 02L-K	☆									☆	☆																☆	☆					TCGT 220L-K		
		TCGT 11 03 02R-K	☆										☆	☆															☆	☆					TCGT 220R-K		
		TCGT 11 03 04L-K	☆										☆	☆															☆	☆					TCGT 221L-K		
		TCGT 11 03 04R-K	☆										☆	☆															☆	☆					TCGT 221R-K		
	06	5/32	TCGX 06 T1 04L-WK	☆									☆	☆														☆	☆						TCGX 1.2(1.2)1L-WK		
			TCGX 06 T1 04R-WK											☆	☆														☆	☆						TCGX 1.2(1.2)1R-WK	
	09	7/32	TCGX 09 02 04L-WK	☆						☆		☆	☆																☆	☆						TCGX 1.8(1.5)1L-WK	
			TCGX 09 02 04R-WK	☆							☆		☆	☆																☆	☆					TCGX 1.8(1.5)1R-WK	
	11	1/4	TCGX 11 02 04L-WK							☆		☆	☆																	☆						TCGX 2(1.5)1L-WK	
			TCGX 11 02 04R-WK								☆		☆	☆																☆						TCGX 2(1.5)1R-WK	
			TCGX 11 03 04L-WK	☆							☆		☆	☆																☆	☆					TCGX 221L-WK	
			TCGX 11 03 04R-WK	☆										☆	☆															☆	☆					TCGX 221R-WK	


For dimensions, see code key on page 114.



 A13



A27

 

A558



I1