

5 Port Pilot Operated Solenoid Valve Metal Seal, Plug-in/Non Plug-in **VFS6000 Series**





How to Order



Plug-in



Non plug-in

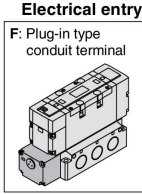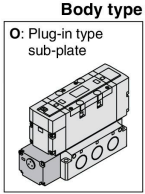

Porting specifications

Nil	Side ported
-----	-------------

Port size

Nil	Without sub-plate
06	3/4
10	1

Thread type

Nil	Rc
N*	NPT
T*	NPTF
F*	G

* Semi-standard

CE-compliant

Nil	—
Q	CE-compliant




VFS6 1 0 0 [] - 5 F Z - [] 10 [] - []

VFS6 1 1 0 [] - 5 D Z - [] 10 [] - []

Option

Nil	None
Z	With light/surge voltage suppressor

Electrical entry

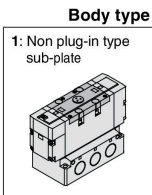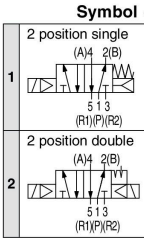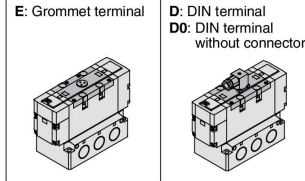

Coil rated voltage

1	100 VAC, 50/60 Hz
2	200 VAC, 50/60 Hz
3*	110 to 120 VAC, 50/60 Hz
4*	220 VAC, 50/60 Hz
5	24 VDC
6*	12 VDC
7*	240 VAC, 50/60 Hz

* Semi-standard
For other rated voltages, please consult with SMC.

Pilot type

Nil	Internal pilot
R*	External pilot

* Semi-standard

Body Option

0	Standard
1*	Direct manual override

* Semi-standard

How to Order Pilot Valve Assembly

SF4 - 1 F - 22

Coil rated voltage

1	100 VAC, 50/60 Hz
2	200 VAC, 50/60 Hz
3*	110 to 120 VAC, 50/60 Hz
4*	220 VAC, 50/60 Hz
5	24 VDC
6*	12 VDC
7*	240 VAC, 50/60 Hz

* Semi-standard
For other rated voltages, please consult with SMC.
** Refer to page 1010 for voltage conversion.

- SV
- SYJ
- SZ
- VF
- VP4
- VQ 1/2
- VQ 4/5
- VQC 1/2
- VQC 4/5
- VQZ
- SQ
- VFS
- VFR
- VQ7

