


# Short Type: $\varnothing 16, \varnothing 20, \varnothing 25, \varnothing 32, \varnothing 40, \varnothing 50, \varnothing 63$

MY3A  -

\* Refer to "Specific Product Precautions" on page 1453 for mounting.

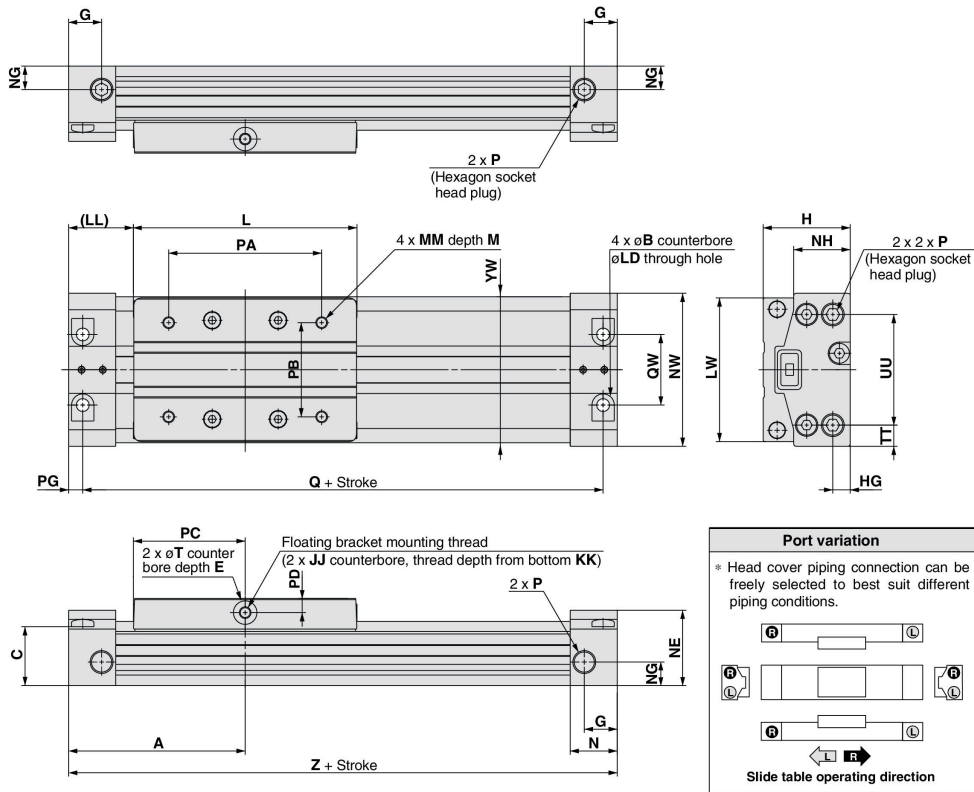

- MY1B
- MY1H
- MY1B
- MY1M
- MY1C
- MY1H
- MY1 HT
- MY1 □W
- MY2C
- MY2 H/HT
- MY3A
- MY3B
- MY3M

(mm)

| Model  | A    | B   | C    | E | G    | H  | HG   | JJ        | KK   | L   | LD  | LL   | LW  | M  | MM        | N    |
|--------|------|-----|------|---|------|----|------|-----------|------|-----|-----|------|-----|----|-----------|------|
| MY3A16 | 55   | 6   | 18   | 2 | 9.5  | 27 | 5    | M4 x 0.7  | 5    | 65  | 3.5 | 22.5 | 41  | 6  | M4 x 0.7  | 13.5 |
| MY3A20 | 64   | 7.5 | 22   | 2 | 9.5  | 32 | 6.5  | M4 x 0.7  | 8.5  | 80  | 4.5 | 24   | 51  | 6  | M4 x 0.7  | 15.5 |
| MY3A25 | 75   | 9.5 | 25   | 2 | 14   | 37 | 7.4  | M5 x 0.8  | 7.5  | 95  | 5.5 | 27.5 | 61  | 8  | M5 x 0.8  | 20   |
| MY3A32 | 96.5 | 11  | 32.5 | 2 | 14   | 45 | 9    | M5 x 0.8  | 7.5  | 128 | 6.6 | 32.5 | 76  | 8  | M5 x 0.8  | 22.5 |
| MY3A40 | 120  | 14  | 38   | 2 | 18   | 54 | 12   | M6 x 1    | 12   | 160 | 8.6 | 40   | 90  | 12 | M6 x 1    | 27   |
| MY3A50 | 137  | 14  | 49   | 3 | 16   | 67 | 14   | M6 x 1    | 15.5 | 190 | 9   | 42   | 112 | 12 | M6 x 1    | 27   |
| MY3A63 | 160  | 17  | 60   | 3 | 20.5 | 84 | 16.5 | M8 x 1.25 | 22   | 220 | 11  | 50   | 134 | 16 | M8 x 1.25 | 31   |

| Model  | NE   | NG | NH   | NW  | P             | PA  | PB | PC   | PD  | PG  | Q   | QW | T  | TT   | UU | YW  | Z   |
|--------|------|----|------|-----|---------------|-----|----|------|-----|-----|-----|----|----|------|----|-----|-----|
| MY3A16 | 22.5 | 8  | 17.2 | 43  | M5 x 0.8      | 44  | 26 | 32.5 | 4   | 4   | 102 | 19 | 7  | 6.5  | 30 | 42  | 110 |
| MY3A20 | 27.5 | 10 | 20.8 | 53  | M5 x 0.8      | 54  | 30 | 40   | 5   | 4.5 | 119 | 23 | 8  | 9    | 35 | 52  | 128 |
| MY3A25 | 32   | 10 | 24   | 65  | Rc, NPT, G1/8 | 64  | 40 | 47.5 | 6   | 6   | 138 | 30 | 10 | 9    | 47 | 62  | 150 |
| MY3A32 | 39   | 14 | 31   | 79  | Rc, NPT, G1/8 | 92  | 44 | 64   | 6   | 7   | 179 | 33 | 10 | 13.5 | 52 | 77  | 193 |
| MY3A40 | 46   | 15 | 37   | 94  | Rc, NPT, G1/4 | 112 | 60 | 80   | 7.5 | 8.5 | 223 | 40 | 14 | 14   | 66 | 92  | 240 |
| MY3A50 | 58   | 25 | 47.5 | 116 | Rc, NPT, G3/8 | 142 | 66 | 95   | 8.5 | 8.5 | 257 | 44 | 15 | 21   | 74 | 114 | 274 |
| MY3A63 | 70   | 29 | 58   | 139 | Rc, NPT, G3/8 | 162 | 84 | 110  | 10  | 10  | 300 | 64 | 16 | 20   | 99 | 136 | 320 |

- D
- X
- Technical Data