

Controller for Electro-Pneumatic Regulator **IC Series**

How to Order

IC 1 0 - 0 - - -

Pressure range

1	0.1 MPa
3	0.5 MPa
5	0.9 MPa
9	-100 kPa

Output specifications

0	NPN open collector output
1	PNP open collector output

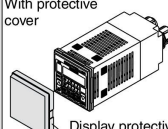
Sensor

0	Built-in sensor type
1	External sensor type

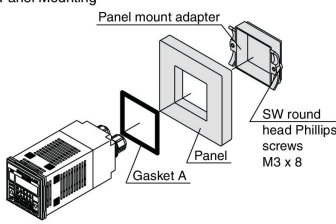
Made to Order

N11	Standard type Button operation is required for start-up when turning the power supply on again.
X2	Automatic reset type Automatically returns to the pre-shutdown state when power is switched on again.

Protective cover (option)

N11	Without
B	With protective cover  Display protective cover

Mounting

N11	Without
A	Panel Mounting  Panel mount adapter Panel Gasket A SW round head Phillips screws M3 x 8

Option

When only optional parts are required, order using the part numbers listed below.

Description	Part no.	Note
Panel mount adapter set	P398050-1	Gasket, Screw 2 pcs.
Display protective cover	P2992136	-

