



M Series

M3 Series


Barb Fitting for Soft Tubing: M-3AU-3

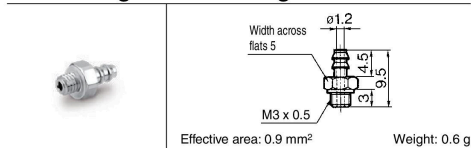


Barb Fitting for Soft Tubing: M-3AU-4

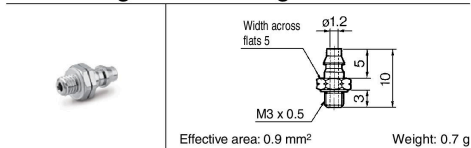


Barb Elbow for Soft Tubing: M-3ALU-3

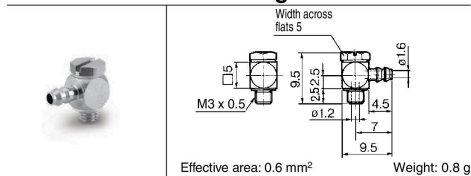


Barb Elbow for Soft Tubing: M-3ALU-4

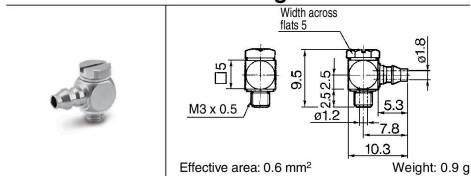


Universal Elbow: M-3UL

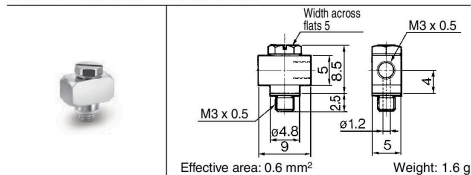


Universal Tee: M-3UT

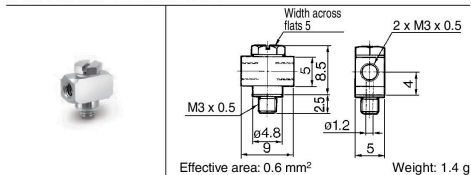

Nipple: M-3N

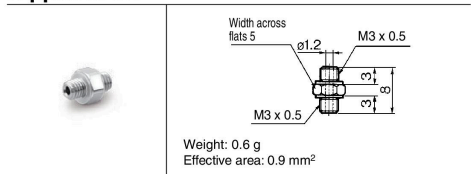


Plug: M-3P

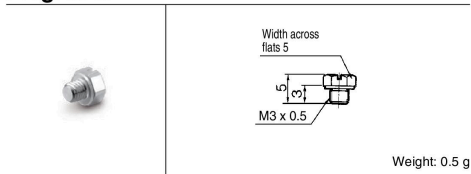

R 1/8 Series

Barb Fitting for Nylon Tubing, Soft Tubing: M-01A□-4/-6

Applicable tubing	Model	A	B	øC	Effective area (mm ²)	Weight (g)
Nylon tubing	M-01AN-4	15.1	5	1.8	2.1	6.4
	M-01AN-6	17.1	7	2.5	4.0	6.6
Soft tubing	M-01AU-4	15.1	5	1.8	2.1	6.5
	M-01AU-6	17.1	7	2.5	4.0	6.7

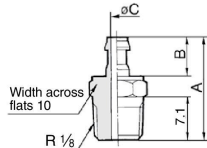

Hose Nipple: M-01H-4/-6

Model	A	B	øC	øD	E	Effective area (mm ²)	Weight (g)
M-01H-4	18.6	8.5	1.8	6.5	7	2.1	7.1
M-01H-6	19.6	9.5	3	8.5	8	5.5	7.7

