


Dimensions

Male Connector: KFG2H



Applicable tubing size (mm)		Connection thread R	Model	Width across flat		L	M	ød	A*	Effective area (mm ²)	Weight (g)	
O.D.	I.D.			H1	H2							
ø4	ø2.5	1/8	KFG2H0425-01	10	8	19.4	5	1.8	16.3	1.6	8	
		1/4	KFG2H0425-02	14		23.8					14	
ø4	ø3	1/8	KFG2H0403-01	10	8	19.4	5	2.3	16.3	2.6	8	
		1/4	KFG2H0403-02	14		23.8					14	
ø6	ø4	1/8	KFG2H0604-01	10	10	20.9	5.8	3.3	17.8	6	10	
		1/4	KFG2H0604-02	14		25.3					16	
ø8	ø6	1/8	KFG2H0806-01	14	14	23.3	6.6	5.3	20.2	17	18	
		1/4	KFG2H0806-02			26.7					22	24
		3/8	KFG2H0806-03			28.1					23	36
ø10	ø7.5	1/4	KFG2H1075-02	17	17	29.7	7.6	6.8	25	30	34	
		3/8	KFG2H1075-03			30.1					27.1	41
		1/2	KFG2H1075-04			33.5					27.1	67
ø10	ø8	1/4	KFG2H1008-02	17	17	29.7	7.3	9	25	35	33	
		3/8	KFG2H1008-03			30.1					27.1	40
		1/2	KFG2H1008-04			33.5					27.1	66
ø12	ø9	1/4	KFG2H1209-02	17	17	31.3	8.5	8	26.6	45	33	
		3/8	KFG2H1209-03			31.7					28.7	40
		1/2	KFG2H1209-04			35.1					28.7	66
ø12	ø10	1/4	KFG2H1210-02	17	17	31.3	9	9	26.6	57	30	
		3/8	KFG2H1210-03			31.7					28.7	38
		1/2	KFG2H1210-04			35.1					28.7	63
ø16	ø13	3/8	KFG2H1613-03	22	22	33.1	9.3	12	28	101	51	
		1/2	KFG2H1613-04			36.3					29.9	67

* Reference dimensions after installation of R thread

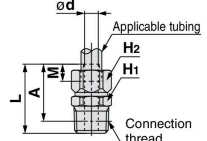


Male Elbow: KFG2L



Applicable tubing size (mm)		Connection thread R	Model	Width across flat		L1	L2	M	ød	A*	Effective area (mm ²)	Weight (g)	
O.D.	I.D.			H1	H2								
ø4	ø2.5	1/8	KFG2L0425-01	10	8	13.5	5	1.8	13.8	1.6	10		
		1/4	KFG2L0425-02								15.9	14	
ø4	ø3	1/8	KFG2L0403-01	10	8	13.5	5	2.3	13.8	2.6	10		
		1/4	KFG2L0403-02								15.9	14	
ø6	ø4	1/8	KFG2L0604-01	10	10	15	5.8	3.3	16	6	12		
		1/4	KFG2L0604-02								17	16	
ø8	ø6	1/8	KFG2L0806-01	12	14	17.4	6.6	5.3	20.4	12	20		
		1/4	KFG2L0806-02								19.2	16	24
		3/8	KFG2L0806-03								19.6	16	27
ø10	ø7.5	1/4	KFG2L1075-02	15	17	20.9	7.6	6.8	25.6	23	38		
		3/8	KFG2L1075-03								21.3	26	41
		1/2	KFG2L1075-04								24.5	27.5	51
ø10	ø8	1/4	KFG2L1008-02	15	17	20.9	7.3	9	25.6	30	37		
		3/8	KFG2L1008-03								21.3	27.5	41
		1/2	KFG2L1008-04								24.5	27.5	50
ø12	ø9	1/4	KFG2L1209-02	16	17	23.5	8.5	8	25.6	27	41		
		3/8	KFG2L1209-03								21.3	35	45
		1/2	KFG2L1209-04								24.5	27.5	57
ø12	ø10	1/4	KFG2L1210-02	16	17	23.5	8.5	9	25.6	34	42		
		3/8	KFG2L1210-03								21.3	44	43
		1/2	KFG2L1210-04								24.5	27.5	53
ø16	ø13	3/8	KFG2L1613-03	21	22	26.2	9.3	12	31	79	72		
		1/2	KFG2L1613-04								27.2	32.9	78

* Reference dimensions after installation of R thread

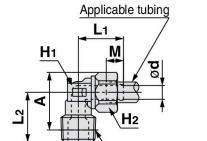

- KQ2
- KQB2
- KS
- KX
- KM
- KF
- M
- H/DL
- L/LL
- KC
- KK
- KK130
- DM
- KDM
- KB
- KR
- KA
- KQG2
- KG
- KFG2
- MS
- KKA
- KP
- LQ
- MQR
- T
- IDK