


How to Order

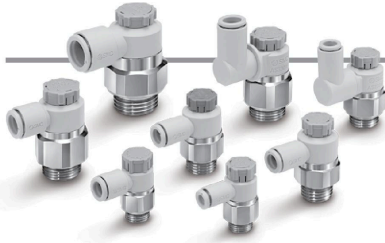

Type

2	Elbow
3	Universal

Thread type

G	G
---	---

G thread

R, NPT thread

Body size

2	1/8, 1/4
3	3/8
4	1/2

Type

2	Elbow
---	-------

Control type

0	Meter-out
1	Meter-in

Thread type

Nil	R
N	NPT

Port size

01	1/8
02	1/4
03	3/8
04	1/2

Seal method

P	Face seal
---	-----------

Applicable tubing O.D. Note 1)

Metric size	Inch size <small>Note 3)</small>
23	01 ϕ 1/8"
04	03 ϕ 5/32"
06	07 ϕ 1/4"
08	09 ϕ 5/16"
10	11 ϕ 3/8"
12	13 ϕ 1/2"
16	ϕ 16 <small>Note 4)</small>

Made to Order
For details, refer to page 571.

Push-lock type

- AS-F
- TMH
- ASD
- AS
- AS-FE
- KE
- AS-FG
- AS-FP
- AS-FM
- AS-D
- AS-T
- ASP
- ASN
- AQ
- ASV
- AK
- VCHC
- ASR
- ASQ



Made to Order
(For details, refer to page 571.)

Symbol	Specifications
-X12	Lubricant: Vaseline
-X21	Grease-free (Seal: Fluorine-coated) + Restrictor (Without check valve)
-X214	Restrictor (Without check valve)
10-	Clean Series