

How to Order

AS 2 2 0 1 F M - [] 01 - 06 [] - [] - []

Body size

1	M5 standard
2	1/8, 1/4 standard

Type

2	Elbow
3	Universal

Control type

0	Meter-out
1	Meter-in

With One-touch fitting

For low speed control

Thread type

Nil	Metric thread (M5)
	Unified thread (10-32 UNF)
N	R
	NPT

Port size

M5	M5 x 0.8
U10/32	10-32 UNF
01	1/8
02	1/4

Option

Nil	None
S	With seal

* M5 and U10/32 are not available with seal.

Lock nut option

Nil	Hexagon lock nut
J	Round lock nut

Made to Order
Refer to the below for details.

Option

Applicable tubing O.D. (Note)

Metric size	Inch size
23	01
04	03
06	05
08	07
10	09
	11

Note) For applicable tubing O.D. selection, refer to the Model on page 716.

* Use $\phi 1/8"$ tube.

- AS-F
- TMH
- ASD
- AS
- AS-FE
- KE
- AS-FG
- AS-FP
- AS-FM
- AS-D
- AS-T
- ASP
- ASN
- AQ
- ASV
- AK
- VCHC
- ASR
- ASQ

Made to Order



Lubricant: Vaseline

X12

Ex.) AS1201FM-M5-23-X12

Grease-free (Seal: Fluorine Coated) + Throttle Valve (Without Check Valve)

X21

Ex.) AS1201FM-M5-23-X21

Note 1) Not particle-free
Note 2) Throttle valve is only compatible with the part no. of the meter-out type.

Throttle Valve (Without Check Valve)

X214


Ex.) AS1201FM-M5-23-X214

Note) Throttle valve is only compatible with the part no. of the meter-out type.


Needle Valve/Flow Rate Characteristics

Note) The flow rate characteristics are representative values.

AS1201FM, AS1211FM
AS1301FM, AS1311FM

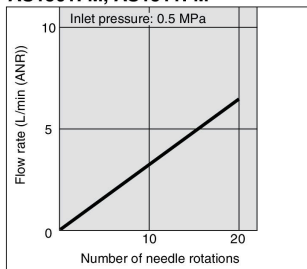

AS2201FM-□01, AS2211FM-□01
AS2301FM-□01, AS2311FM-□01

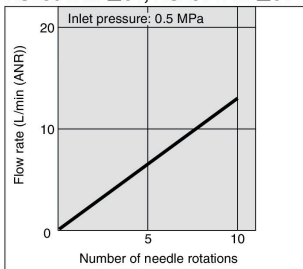

AS2201FM-□02, AS2211FM-□02
AS2301FM-□02, AS2311FM-□02

