

Silent Smooth Castors II



—Twin wheeled compact heavy duty type—

RoHS compliant products.

POINT


- **Excellent swiveling performance** and **extremely low starting resistance** compared to our compact heavy duty castors.
- Wheel with grease-packed precision ball bearings.
– **Smooth and silent rolling** without subsequent lubrication.
- Electrically conductive nylon as one of possible countermeasures against static electricity/ MCD.
- Thanks to **combination of thrust bearing and ball bearing** in the swivel head, it **moves lightly and turns easily** even with a heavy load.
- **Rotates smoothly** after a long-term fixation under a heavy load.

USE EXAMPLE

- For fixed precision machines to be occasionally relocated in a workplace, or moved as production line is rearranged.
- For heavy duty slow-moving carriers.

©We'll accept your custom-order. Please feel free to contact us.
(Use "Specification Form for Custom-designed castor" at the end of this catalog.)
©Please feel free to ask about the product weight for each item.

Starting resistance to a right angle is down compared to a single wheeled castor!

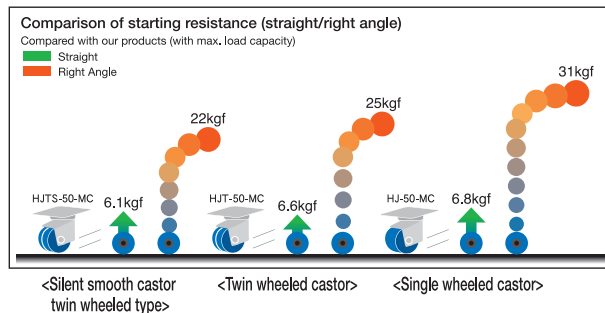

HJTS Swivel castors



HJTS-50

HJTS-65

HJTS-75

• Color/Finish; Zinc plated with CrIII/White coating/Black coating/Chromium plated

HJT SB Swivel with stopper



HJT SB-50

HJT SB-65

HJT SB-75

HJTS-SJ Threaded stem fitting



HJTS-SJ-50

HJTS-SJ-65

HJTS-SJ-75

• Color/Finish; Zinc plated with CrIII/Black coating

HJT SB-SJ Threaded stem fitting with stopper



HJT SB-SJ-50

HJT SB-SJ-65

HJT SB-SJ-75

WHEELS

JBB ...Radial ball bearing

See P.62 to P.71 for detailed description.



MC (Monomer cast nylon/Blue)

JBB



MCMO (Monomer cast nylon/Black)

JBB



MCD (Conductive monomer cast nylon/Black)

JBB

• Volume resistance $10^2 \sim 10^4 \Omega \cdot \text{cm}^*$

*For reference only, not guaranteed.

NB Bracket Color/Finish; Zinc plated with CrIII only.