



Adaptor Plate

■ Adaptor plate
A49-50B-1/A49-50

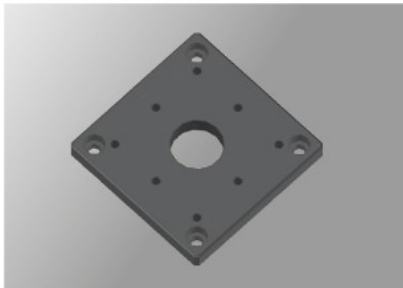


This black adaptor plate is attached 40 x 40mm stage on a 50 x 50mm stage.


※White almite treatment for A49-50

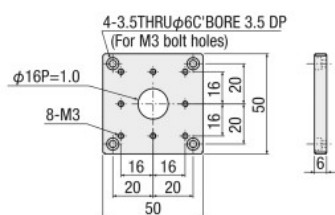

■ Adaptor plate
A49-50B-2

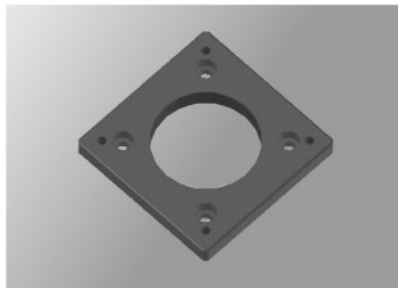


This black adaptor plate is attached 50 x 50mm stage on a 40x40 • 60x60 • φ60 • φ75mm stage.

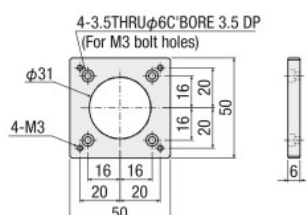


■ Adaptor plate
A49-70




This is a white adaptor plate for attachment 70 x 70mm and 60 x 60mm stage.

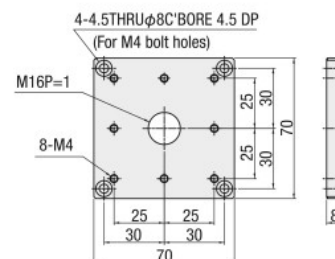


■ Adaptor plate
A49-70B-1

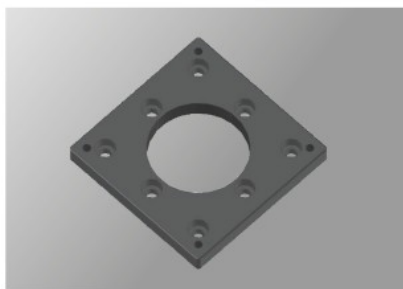



This black adaptor plate is attached 70 x 70mm stage on a 60x60 • 80x80 • 100x100mm • φ75 • φ100mm stage.

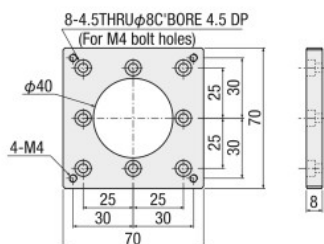

■ Adaptor plate
A49-80

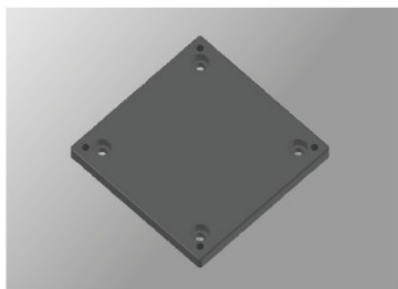

This black adaptor plate is attached 70x70mm on a 80x80mm stage and φ75mm rotation stage.

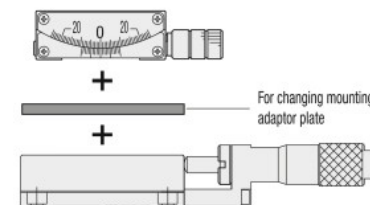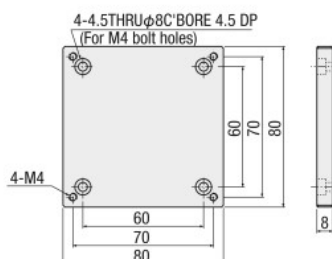

SPEC						
Model	A49-50B-1	A49-50B-2	A49-50	A49-70	A49-70B-1	A49-80
Main material—Surface finishing	Aluminum—Black alumite processing	Aluminum—Black alumite processing	Aluminum—White alumite processing	Aluminum—White alumite processing	Aluminum—Black alumite processing	Aluminum—Black alumite processing
Weight	0.05kg	0.05kg	0.05kg	0.11kg	0.11kg	0.13kg
Provided screws (Hex socket screws)	4 of M3—8	4 of M3—8	4 of M3—8	4 of M4—8	4 of M4—8	4 of M4—8