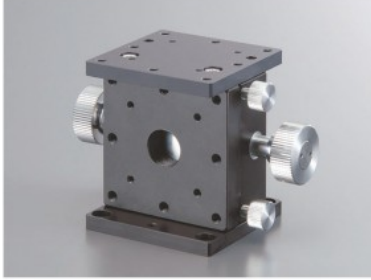


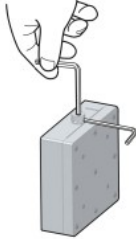



Type	Product image	Features
Rack and pinion Feeding screw Short lead	Stage table size □60mm B06-13Z 	【Features】 • Available mounting horizontal and vertical.
	B06-13BZ 	
	Stage table size □60mm B08-113 	【Features】 • Lead 0.5mm feeding screw XY-axis stage with Z-axis bracket. • Saving-space and prevention error operation by using hex wrench type. 
	BDBZS-60 	

■ Configuration

Model	B06-13Z	B06-13BZ	B08-113	BDBZS-60
Bracket /Reference page	—	—	A47-3/ P.2-179	A47-3/ P.2-179
X-axis/Reference page	—	—	B08-111/ P.2-103~	BDBXS-60/ P.2-103~

SPEC				
Model	B06-13Z	B06-13BZ	B08-113	BDBZS-60
(Opposite hand)	B06-13ZR	B06-13BZR	B08-113R	—
Stage table size	60×60mm			
Travel distance	+20mm		±9mm	±7mm
Travel distance per rotation of knob	18mm	Rough:18mm micromotion:±2.3mm		0.5mm
Minimum reading capability	Vernier scale 0.1mm			
Load capacity	2.0kgf [19.6N]			
Travel accuracy	Straightness 30μm			
Allowable load for moment	Pitch	7.0N · m		5.0N · m
	Yaw	5.0N · m		4.0N · m
	Roll	7.0N · m		4.0N · m
Weight	0.60kg	0.52kg	0.75kg	0.67kg
Main material — Surface finishing	Aluminum — Black alumite processing		Brass — Black coating finish	
Provided screws (Hex socket screws)	4 of M4—6		4 of M4—10	