



SSP8


## SSP

### SHOCK SPEED PULLER SET (Heavy Duty Type for Professional Use)

#### ► Features

- Outstanding pulling force for burned or rusted gears or pulleys, by giving impacts to the forcing screw with a hammer (No other pullers have this unique mechanism).
- Steel case as standard acc.
- H indicates the claw reaching length when, with D at shortest length, the forcing screw is lifted to the highest point.

#### ► Example of use

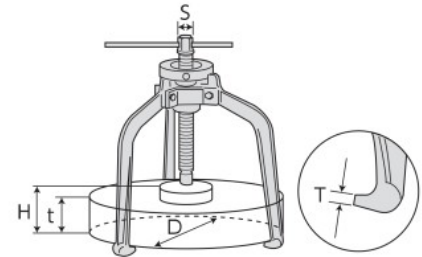

#### ► Accessories

GP grease  
(10g)  
(all size)



Hex key wrench  
(all size)



Super head spanner  
(SSP5-8)



Single-size ratchet  
wrench with grip  
(SSP12)



| Item No. | Size (mm)                   |   |                           |                         |  |                    | Guaranteed load (kN) | Set N.W. (kg) |
|----------|-----------------------------|---|---------------------------|-------------------------|--|--------------------|----------------------|---------------|
|          | D<br>Pulled object diameter | t<br>Pulled object width when D at max. | H<br>Claw reaching length | T<br>Claw tip thickness | S<br>Forcing screw hex. width across flats | Forcing screw dia. |                      |               |
| SSP5     | 55~125                      | 125                                     | 140                       | 5                       | 19   | 18                 | 50                   | 3             |
| SSP8     | 80~200                      | 175                                     | 200                       | 7                       | 22   | 22                 | 100                  | 6             |
| SSP12    | 120~300                     | 225                                     | 270                       | 9                       | 32   | 32                 | 200                  | 17            |

## SPSR · SPJ · SPN · SPA · SPB · SPH · SPU

### SHOCK SPEED PULLER Parts




SPSR5

full length

■ Forcing screw, body (with adaptor)
 
| Item No. | Full length (mm) |
|----------|------------------|
| SPSR5    | 208              |
| SPSR8    | 270              |
| SPSR12   | 355              |



SPJ5

full length

■ Claw (1 pc)

| Item No. | Full length (mm) |
|----------|------------------|
| SPJ5     | 210              |
| SPJ8     | 296              |
| SPJ12    | 400              |



SPN5

full length

■ Pin (1 pc)

| Item No. | Full length (mm) |
|----------|------------------|
| SPN5     | 33.5             |
| SPN8     | 44.5             |
| SPN12    | 66.4             |



SPA5

■ Adjustment screw

| Item No. |
|----------|
| SPA5     |
| SPA8     |
| SPA12    |



SPB5

■ Body

| Item No. |
|----------|
| SPB5     |
| SPB8     |
| SPB12    |



SPH5

■ Auxiliary adaptor with step

| Item No. | Size (mm) |    |    |
|----------|-----------|----|----|
|          | L         | D  | D1 |
| SPH5     | 45        | 18 | 10 |
| SPH8     | 60        | 20 | 13 |
| SPH12    | 85        | 26 | 15 |



SPU5

■ Handle

| Item No. |
|----------|
| SPU5     |
| SPU8     |
| SPU12    |