 


Digital Caliper with Hold Function

 
Includes storage case



19986



19987



19988



Item Code	Description	Body Size (mm)	Weight (g)	JAN Code	Packing Unit	Packaging
19986	450 mm	626×169×20	980	4 960910 199866	1	
19987	600 mm	776×169×20	1,100	4 960910 199873		
19988	1000 mm	1,233×216×26	2,400	4 960910 199880		

Features

- Ideal for precision work with a minimum reading value of 0.01 mm
- Zero set function enables relative measurement or indirect measurement
- Hold function is useful when the screen cannot be seen
- Fine adjustment knob makes adjustment easy
- ABS function that can set the display to 0.00 without changing the measurement origin
- Preset function enables to adjust zero point in 0.01 mm units




- Long jaws that match the length of the main body for measuring deeper and larger parts



Use

- For measuring outside, inside, and gap
- For relative measurement and indirect measurement

Specifications

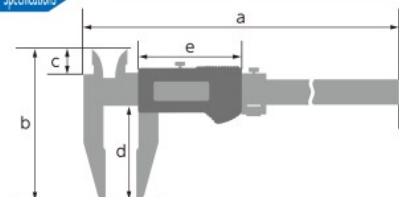

Item Code	19986	19987	19988
Body Size	a 626 mm	a 776 mm	a 1,233 mm
	b 169 mm	b 169 mm	b 216 mm
	c 38 mm	c 38 mm	c 50.8 mm
	d 100 mm	d 100 mm	d 125 mm
	e 100 mm	e 100 mm	e 130 mm
	f 24 mm	f 24 mm	f 31 mm
Measuring Range	0.01 - 450 mm	0.01 - 600 mm	0.01 - 1,000 mm
Minimum Reading	0.01 mm		
Depth Probe	None		
Fine Adjustment Function	Attached		
Preset Function	Attached		
Accuracy	±0.05 mm		±0.10 mm
Use Temperature	0 - 40°C		
Storage Temperature	-10 - 60°C		
Storage Humidity	Below 80%		
Battery	1x Lithium battery CR2032 (Battery included is for trial use only and may not last as long)		
Material	Body: Stainless steel Digital Module: ABS resin		