

低床式重荷重用自在キャスター 低床式重荷重用固定キャスター

LOW-PROFILE HEAVY-DUTY SWIVEL AND RIGID CASTERS

K-1540S
ステンレス製

K-540S
鉄製

K-1540SR
ステンレス製

K-540SR
鉄製


特 徴 Feature

- 取付け高さが低く、重荷重に十分耐えられます。
- 車輪は重荷重で長時間固定されても歪みは残りません。
- ブラック仕上げですのでOA機器にマッチします。(K-540)
- Installing height is small so it withstands heavy load.
- No distortions occur even if it's fixed with heavy load for long periods.
- Black finish matches OA equipment. (K-540)

[K-1540]

仕 様 ●材 質：本体/ステンレス鋼板(SUS304)
車輪/ナイロン(ベアリング入)

[K-540]

仕 様 ●材 質：本体/冷間圧延鋼板(SPCC)
車輪/ナイロン(ベアリング入)
●表面仕上：本体/亜鉛めっき黒色クロメート処理(MFZn-C)
用 途 ●OA機器・大型・中型の機器
納 期 ●標準品・・・納期お問合せ下さい

[K-1540]

Speci- ●Material: Main body: Stainless steel plate (SUS304)
fications Wheel: Nylon (with bearings)

[K-540]

Speci- ●Material: Main body: Cold rolled steel plate (SPCC)
fications Wheel: Nylon (with bearings)
●Finish: Main body: Zinc plating black chromate treatment (MFZn-C)

Specific use ●OA equipment, large and middle-sized equipment



K-1540S-75-NRB



K-1540SR-75-NRB




K-540S-75-NRB








K-540SR-75-NRB

[K-1540S]
[K-540S]

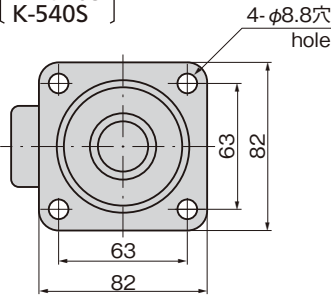

[K-1540SR]
[K-540SR]

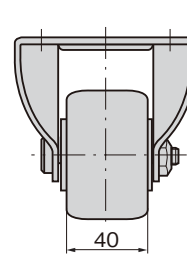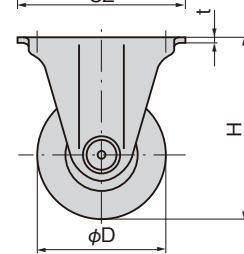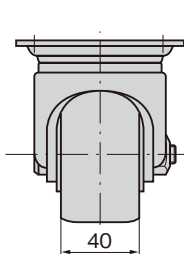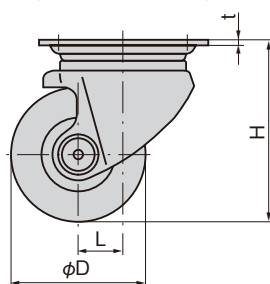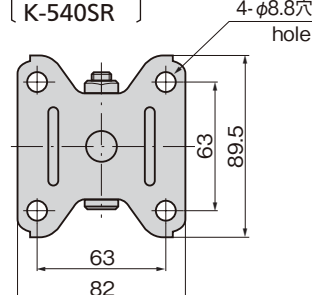

[自在車] Swivel type

商品番号 Product No.	RoHS	CAD	備 考 Remarks	φD	H	L	t	旋回半径 Slewing radius	許容荷重kN Allowable load	製品質量(g) Mass	コード Code	単 価 Price	量販価格 Bulk Price 数量 Quantity 単価 Price
K-1540S-65-NRB	●	2D/3D	ステンレス製 Stainless steel	65	90	22	3	58	2.94	875	31753	¥5,300	8個～ ¥5,090
K-1540S-75-NRB	●	2D/3D	ステンレス製 Stainless steel	75	100	23	3	63	2.94	941	31754	¥5,500	8個～ ¥5,280
K-540S-65-NRB		2D/3D	鉄製 Iron	65	90	22	3.2	58	2.74	850	31004	¥2,500	6個～ ¥2,425
K-540S-75-NRB		2D/3D	鉄製 Iron	75	100	23	3.2	63	2.94	910	31005	¥2,600	6個～ ¥2,522

●: RoHS指令対応品 ▲: RoHS指令に対応可能です。

※大量のご注文は更にお安くなります。

[固定車] Rigid type

商品番号 Product No.	RoHS	CAD	備 考 Remarks	φD	H	t	許容荷重kN Allowable load	製品質量(g) Mass	コード Code	単 価 Price	量販価格 Bulk Price 数量 Quantity 単価 Price
K-1540SR-65-NRB	●	2D/3D	ステンレス製 Stainless steel	65	90	3	2.94	547	31755	¥4,500	8個～ ¥4,320
K-1540SR-75-NRB	●	2D/3D	ステンレス製 Stainless steel	75	100	3	2.94	609	31756	¥4,700	8個～ ¥4,512
K-540SR-65-NRB		2D/3D	鉄製 Iron	65	90	3.2	2.74	590	31006	¥2,000	12個～ ¥1,940
K-540SR-75-NRB		2D/3D	鉄製 Iron	75	100	3.2	2.94	700	31007	¥2,200	6個～ ¥2,134

●: RoHS指令対応品 ▲: RoHS指令に対応可能です。

※大量のご注文は更にお安くなります。


K

 HEAVY-DUTY CASTERS
重荷重用
キャスター
キャスター
双輪
キャスター
緩衝器付
キャスター
アジャスター付
キャスター

 戸車
ボール
キャスター
モニター
アーム
レベル
アジャスター
ペダル
ロック
ステップ
スライド
レール